


Type: **020811080**External dimensions: **75 x 110 x 75 mm**Weight: **440 g**



DIN rail length in mm	max. fitting length in mm	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	Allen lid screws	Silicone lid seal	Sealable lid screws
TS 15								
98	79	2	•		•	•	•	•

Lid

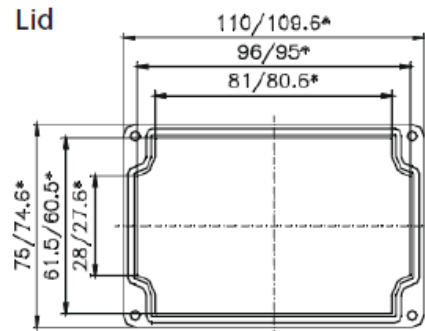


* = Conical form tapering downwards
Free dimensions-tolerance to DIN 16901 - 130

Cylinder screw
M4x24/7
similar to DIN 84

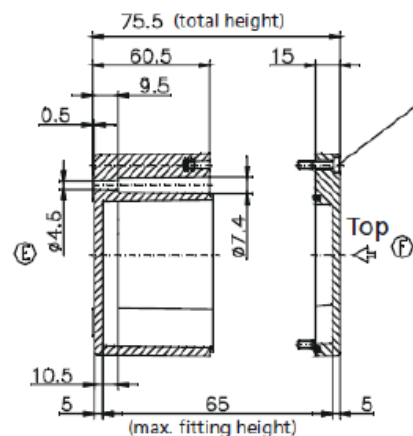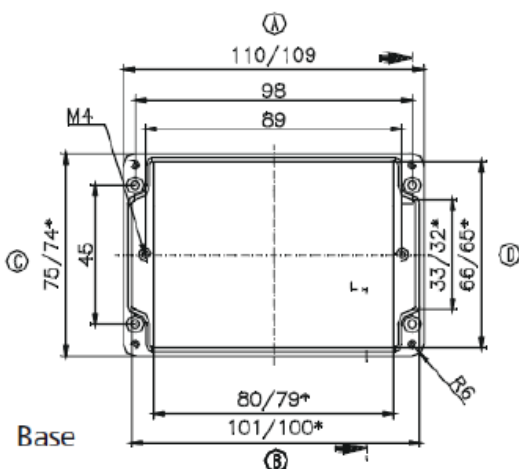

 Maximum number of cable glands to DIN 50262*



M	Corner dim.	Side		PG	Corner dim.	Side	
		A/B	C/D			A/B	C/D
12	17.25	15	5	7	17,25	15	5
16	25.30	6	2	9	21,85	9	3
20	27.60	6	1	11	25,30	6	2
25	37.95	2	1	13.5	27,60	6	1
32	48.30	2	1	16	31,05	5	1
40	60.95			21	37,95	2	1
50	69.00			29	48,30	2	
63	74.75			36	60,95		
				42	69,00		
				48	74,75		

DATE	17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	
SHEET	1		
DESCRIPTION		ENCLOSURE, STANDARD, FIBERGLASS 75 X 110 X 75MM, RAL 7000	
SIZE	DRAWING NUMBER		REV
A	020811080		-