


**Part Number :** [740760005](#)

**Product Description :** VHDM-HSD Free-Standing Guide Pin

**Series Number :** 74076

**Status :** Obsolete

**Product Category :** Backplane Connectors

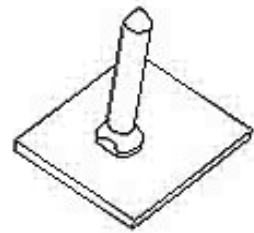

---

## Documents and Resources

### Drawings

[740760005\\_sd.pdf](#)


### Specifications

[PS-74031-999-001.pdf](#)

---

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## Substances of Interest

- PFAS

## EU RoHS Certificate of Compliance

## Additional Product Compliance Information

---

### Part Details

#### General

Status	Obsolete
Category	Backplane Connectors
Series	74076
Description	VHDM-HSD Free-Standing Guide Pin
Application	Backplane
Comments	Dimension C = 6/8 row
Component Type	Guide
Product Name	VHDM,VHDM-HSD
UPC	883906461713

#### Agency

UL	E29179
----	--------

#### Electrical

Current - Maximum per Contact	N/A
Data Rate	N/A
Shielded	No
Voltage - Maximum	N/A

#### Physical

Circuits (Loaded)	0
Circuits (maximum)	0
Durability (mating cycles max)	200
Flammability	94V-0
Guide to Mating Part	Yes
Keying to Mating Part	No
Net Weight	2.608/g

Number of Columns	N/A
Number of Pairs	Open Pin Field
Number of Rows	0
Orientation	N/A
Packaging Type	Bag
PCB Locator	Yes
PCB Retention	No
PCB Thickness - Recommended	1.80mm, 4.00mm
PC Tail Length	N/A
Pitch - Mating Interface	N/A
Pitch - Termination Interface	N/A
Temperature Range - Operating	N/A

---

This document was generated on Apr 13, 2026

Obsolete