


TACT Switch™ Surface Mount Type

3.9×2.9mm (Surface Mount)

SKRK Series

Short-stroke type with 0.13mm travel and heights of 1.5mm & 2.0mm.

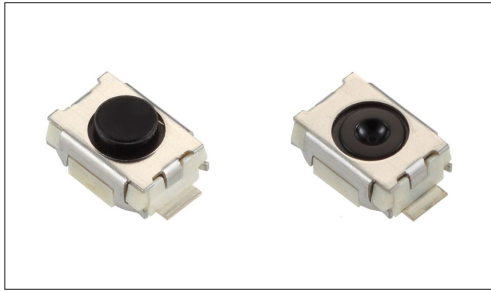

- Series type: Sharp feeling type
- Absolute Maximum Ratings: 50mA 12V DC
- Rating (min.): 10μA 1V DC

Applications: Mobile: Notebooks, peripherals
Energy_Industrial: Robots, drones, Industrial equipment, Converters

■ Product List

Products No.	Operating direction	Operating force (N)	Travel (mm)	Operating life (cycles)	Initial contact resistance	Dimensions (W×D×H) (mm)	Water-proof	Dust-proof	Automotive	Drawing No.
SKRKAHE020	Top push	0.98	0.13	200,000	500mΩ max.	3.9×2.9×2.0	—	—	—	1
SKRKAEE020	Top push	1.57	0.13	200,000	100mΩ max.	3.9×2.9×2.0	—	—	—	
SKRKAGE020	Top push	1.57	0.13	200,000	100mΩ max.	3.9×2.9×1.5	—	—	—	2


⚠ Note

1. This catalog shows only outline specifications. When using the products, please obtain formal specifications for supply.
2. Please place purchase orders for taping products per minimum order unit (1 reel or a case).

■ Packing Specifications


Taping

Products No.	Number of packages(pcs.)			Tape width (mm)	Export package measurements (mm)
	1 reel	1 case / Japan	1 case / export packing		
SKRKAHE020 SKRKAEE020	4,500	45,000	45,000	12	395 x 395 x 205
SKRKAGE020	5,000	50,000	50,000	12	395 x 395 x 205

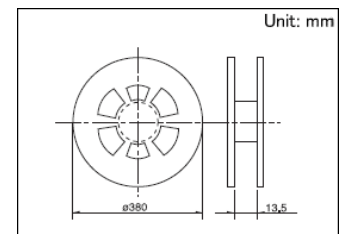


Drawing No. 1

■ Dimensions

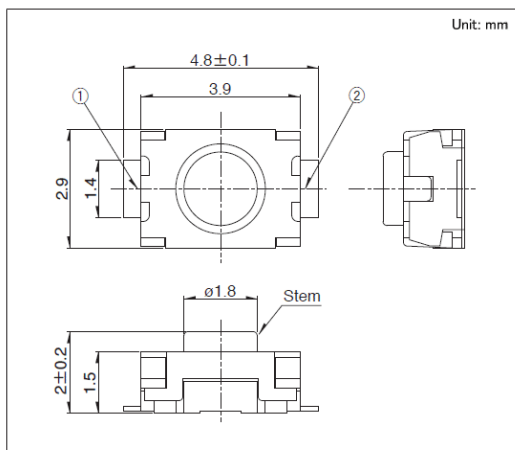


■ Land Dimensions

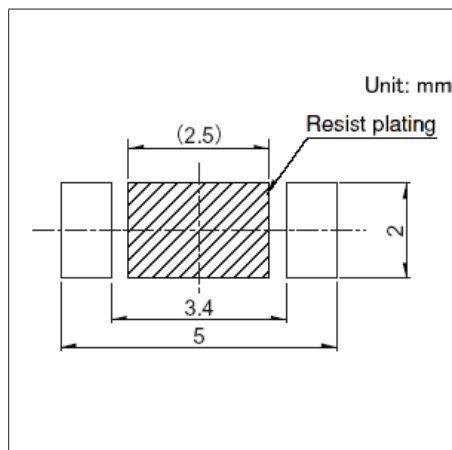

Viewed from mounting face.

■ Circuit Diagram

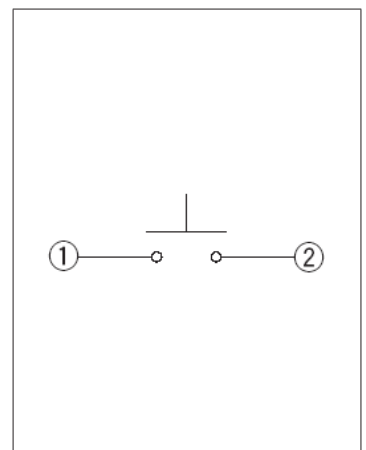


TACT Switch™ Surface Mount Type

3.9×2.9mm (Surface Mount)


SKRK Series

Drawing No.2


■ Dimensions

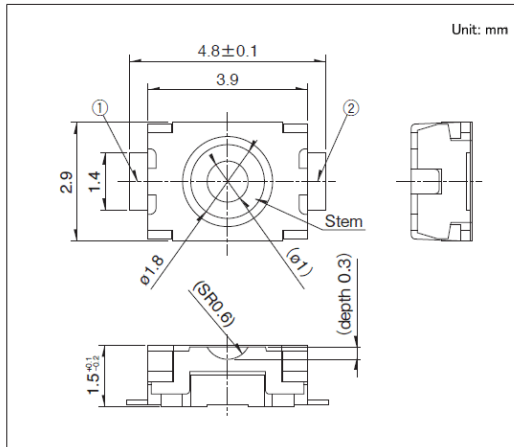

■ Land Dimensions

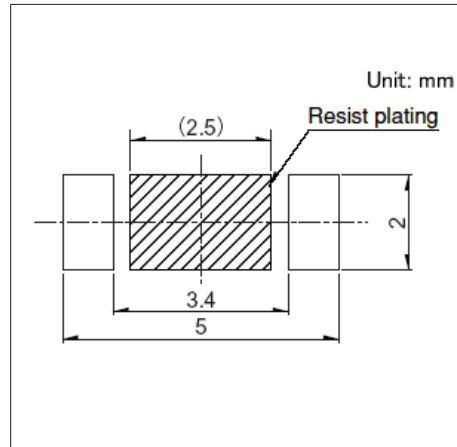

■ Circuit Diagram

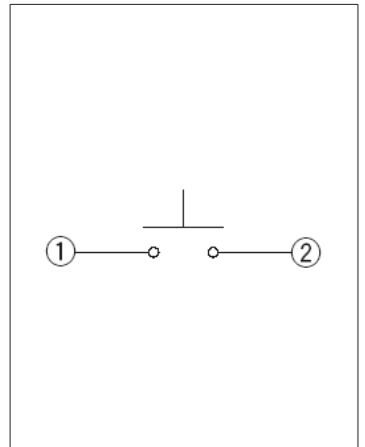

Viewed from mounting face.