

Signal lamp with integrated LED, 10 mm, round bezel, 24-28 V, 28 Volt, bezel yellow, Flat quick-connect terminal 2.8 x 0.8 tin-plated



Description

Signal lamps with integrated LED, mounting hole diameter 10 mm



technical data

> general

Bezel color	yellow	direct links
Property of bezel / mushroom	transparent	
Bezel shape	round	> RAFI eCatalog
illuminated	Yes	
Packaging unit	10 pcs.	
Net weight	2.4 g	
Degree of protection, front side, according to DIN EN 60529	IP40	
Minimum order quantity (MOQ)	50 pcs.	
RoHS compliant	Yes	
REACH compliant	Yes	
Country of origin	HU	

> mounting diameters

Outside dimension, length	12.5 mm
Outside dimension, width	12.5 mm
Outside dimension, height	33.7 mm
Mounting hole	10 mm
Mounting depth	30.5 mm
Installation height	3.2 mm
Collar dimension	12.5 mm

> mechanical data


Terminal on the rear	Flat quick-connect terminal 2.8 x 0.8 tin-plated
Fixing	Pushing into mounting hole
Solderability	Yes

> **electrical data**

Operating voltage of the luminous element, min.	24 V
Operating voltage of the luminous element, max.	28 V
Protective diode	Yes

drawings

Dimensioned drawing

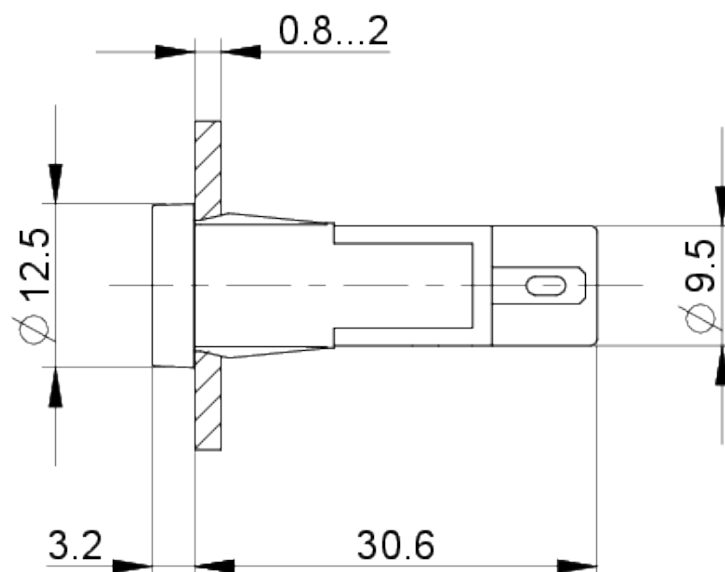

Mounting hole drawing

