


Data Sheet | Item Number: 288-815

stabilized power supply; Input voltage: 230 VAC; ± 15 VDC output voltage; 2 x 0.5 A output current; in mounting carrier; 2,50 mm²

<https://www.wago.com/288-815>



Similar to illustration

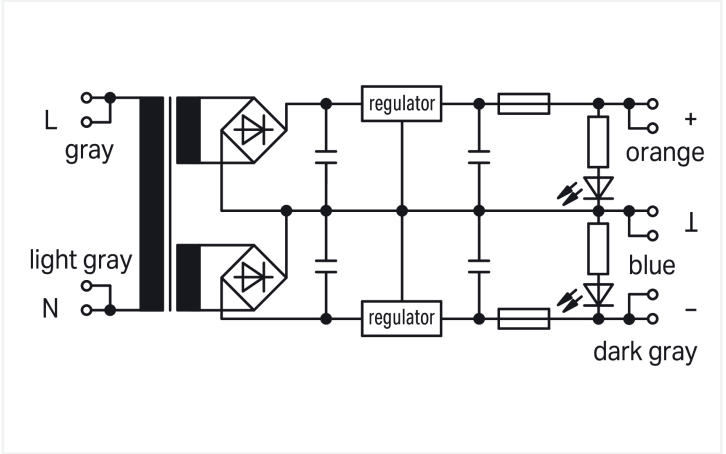

Technical data

Input		Output	
Phases	1	Nominal output voltage $U_{o\ nom}$	15 / -15 VDC
Nominal input voltage $U_{i\ nom}$	1 x 230 VAC	Output voltage range	$\pm 4\%$
Input voltage range	$\pm 10\%$	Nominal output current $I_{o\ nom}$	2 x 0.5 A
Nominal mains frequency range	50 ... 60 Hz	Residual ripple	$\leq 10\text{ mV}$ (peak-to-peak)

Efficiency/power losses		Circuit protection	
Power loss (max.) $P_{I\ (max.)}$	27 W	Internal fuse	2 x T 0.8 A

Safety and protection	
Protection class	III
Protection type	IP00; per EN 60529
Pollution degree	2
Series operation	No

Connection data		Connection 1	
Note (conductor cross-section)	12 AWG: THHN, THWN	Connection technology	CAGE CLAMP®
		WAGO connector	WAGO 236 Series
		Solid conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
		Fine-stranded conductor	0.08 ... 2.5 mm ² / 28 ... 12 AWG
		Strip length	5 ... 6 mm / 0.2 ... 0.24 inches



Physical data		
Width		94 mm / 3.701 inches
Height		106 mm / 4.173 inches
Depth from upper-edge of DIN-rail		57 mm / 2.244 inches

Mechanical data		
Housing design		Mounting carrier
Mounting type		DIN-35 rail

Material data		
Fire load		1.401 MJ
Weight		681.8 g

Environmental requirements		
Ambient temperature (operation)		0 ... +40 °C

Standards and specifications		
Conformity marking		CE

Commercial data		
Product Group		6 (INTERFACE ELECTRONIC)
PU (SPU)		1 pcs
Packaging type		Box
Country of origin		DE
GTIN		4050821155515
Customs tariff number		85044083900

Product classification		
UNSPSC		39121004
eCl@ss 10.0		27-04-07-01
eCl@ss 9.0		27-04-07-01
ETIM 9.0		EC002540
ETIM 8.0		EC002540
ECCN		NO US CLASSIFICATION

Environmental Product Compliance		
CAS-No.		7439-92-1 79-94-7
REACH Candidate List Substance		2,2',6,6'-tetrabromo-4,4'-isopropylidenediphenol Lead
RoHS Compliance Status		Compliant,With Exemption
RoHS Exemption		7(a) 7(c)-I 7(c)-II
SCIP notification number (Austria)		318d28b4-169d-4049-8c49-476eddad18b8
SCIP notification number (Belgium)		613a637d-4cf1-44f4-8aee-1f20e883f629
SCIP notification number (Bulgaria)		a52b8aa0-1e85-4b7b-9408-ae8bf205c29a
SCIP notification number (Czech Republic)		188232d1-ecbb-4dab-b6c5-79a03e4c0ac1
SCIP notification number (Denmark)		7eddfda7-823f-47b1-9428-8fd062091992
SCIP notification number (Finland)		8ce47e0d-653c-44cc-acaf-383ddb7b871b
SCIP notification number (France)		376a5b24-1909-4c4c-9a6d-eb10d31eba1f
SCIP notification number (Germany)		4bde2143-59f5-4405-b2d5-7f34018fa910



Environmental Product Compliance	
SCIP notification number (Hungary)	32cc4aa5-ea72-4a2b-a088-b314e0af0fec
SCIP notification number (Italy)	6728f342-a3ef-4823-81a5-78826fd022e7
SCIP notification number (Netherlands)	6f6c0920-8845-41ba-8cbf-7d755aa9a645
SCIP notification number (Poland)	f593958d-bc0f-4899-a114-ddbbc7836865
SCIP notification number (Romania)	4a822f3e-e573-42a6-bc38-59de3d7e2a31
SCIP notification number (Sweden)	64c53bfe-6174-4ed9-8e80-34ab7f8367dd

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
EAC GZO Almaty Standart	TP TC 020/2011	EAC CoC 03081

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 288-815

↓

Documentation			
Bid Text			Instruction Leaflet
288-815	19.02.2019	xml 3.62 KB	Operation and Assembly Instructions Interface V 1.0.0 02.04.2025 pdf 1246.19 KB
288-815	06.02.2015	doc 25.50 KB	↓

CAD/CAE-Data

CAE data

EPLAN Data Portal 288-815

↓

WSCAD Universe 288-815

↓



1 Compatible Products

1.1 Optional Accessories

1.1.1 Marking

1.1.1.1 Marking strip



Item No.: 709-196
Marking strips; for laser printer; translucent



Item No.: 210-831
Marking strips; on reel; 2.3 mm wide; plain; Self-adhesive; white



Item No.: 210-832
Marking strips; on reel; 3 mm wide; plain; Self-adhesive; white



Item No.: 709-177
Marking strips; on reel; 7.5 mm wide; not stretchable; plain; snap-on type; translucent



Item No.: 709-178
Marking strips; on reel; 7.5 mm wide; not stretchable; plain; snap-on type; white

1.1.2 Tool

1.1.2.1 Operating tool



Item No.: 210-720
Operating tool; Blade: 3.5 x 0.5 mm; with a partially insulated shaft; multicoloured