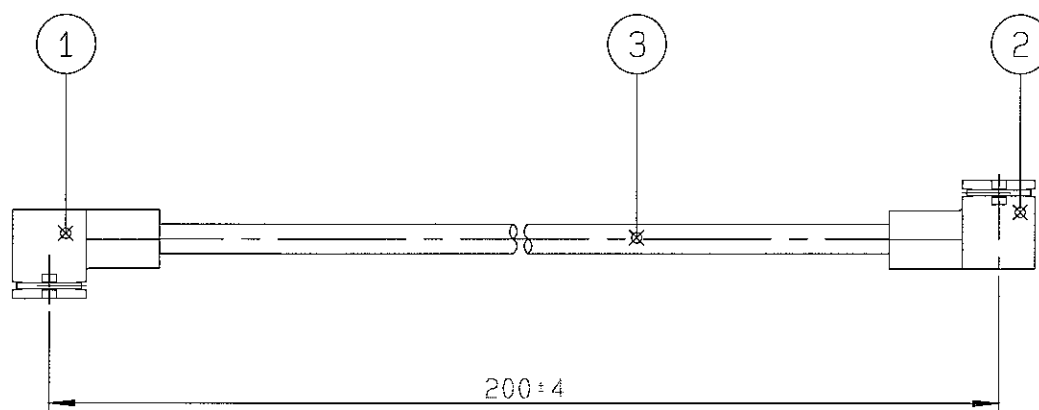


RIGHT ANGLE M MMT - RIGHT ANGLE M MMT**R285.012.221****CABLE 2/50 S-BR - 200MM****Series : CORD-SPECIF**

* 1 * Connector A : **R210.153.000**
 * 2 * Connector B : **R210.153.000**
 * 3 * Cable : **C291.145.060**
 Type : **CAB HF 2/50 RG178 LOW COST - NOIR**

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+80 °C
VSWR	1.10 + 0 x F(GHz) Maxi
Insertion loss	0.404 $\sqrt{F}$(GHz) dB Maxi
Voltage rating	170 Veff Maxi
Dielectric withstanding voltage	500 Veff mini
Insulation resistance	1000 MΩ mini

SPECIFICATION

Weight	3 g
Cable retention	20 N mini
Others :	-

**Edition : 0108 A**

Design changes may be in order to improve the product.