




Order Code	TCK-145
Inductance	6.8 μ H $\pm$ 20% (at 1 kHz / 1 V)
Impedance (DCR)	300 m Ω max.
Rated Current	1 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-145





Impedance Curve

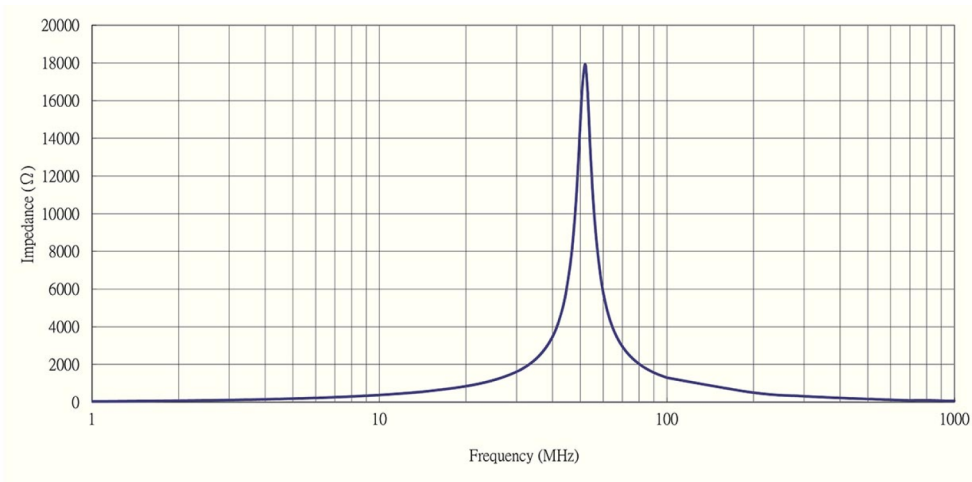

Outline Dimensions

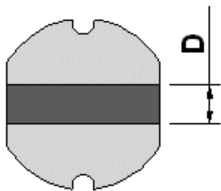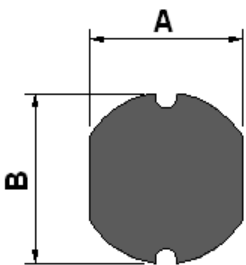

Dimensions [mm]	
A	3.1 $\pm$ 0.5
B	3.5 $\pm$ 0.5
C	2.1 $\pm$ 0.5
D	1.2 typ.
E	3.6
F	1.7
G	0.8

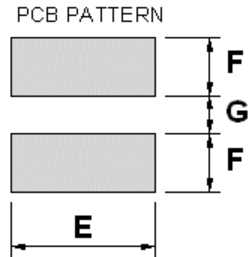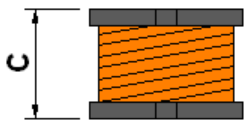

All specifications valid at +25°C, unless otherwise stated.