

Part Number : [1300110124](#)


Product Description : Mini-Change B-Size Double-Ended Cordset, 8 Poles, Male (Straight) to Female (Straight), 16 AWG, Yellow PVC Cable, 3.66m (12.0') Length

Series Number : 130011

Status : Active

Product Category : Circular Industrial Cordsets

Engineering Part Number : 228020A01F120

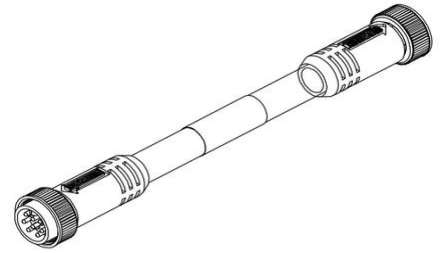


Documents and Resources

Drawings

[1300110124_sd.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Not Relevant |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Contains Lead per D(2023)3788-DC (14 Jun 2023) |
| EU RoHS | Compliant with Exemption 6(c); 6(a)-I per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration

- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | Circular Industrial Cordsets |
| Series | 130011 |
| Description | Mini-Change B-Size Double-Ended Cordset, 8 Poles, Male (Straight) to Female (Straight), 16 AWG, Yellow PVC Cable, 3.66m (12.0') Length |
| IP Rating | IP67 |
| Product Name | Mini-Change |
| Protocol | FF |
| Type | Double Ended |
| UPC | 78678844057 |

Agency

| | |
|-----|---------|
| CSA | LR6837 |
| UL | E152210 |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 7.0A |
| Voltage - Maximum | 600V |

Physical

| | |
|----------------------|-----------------|
| Cable Diameter | 15.49mm (.610") |
| Cable Length | 3.66m (12.0') |
| Color - Cable Jacket | Yellow |
| Connector End A | Mini-Change |

| | |
|-------------------------------|-------------------------|
| Connector End B | Mini-Change |
| Coupling Style | Threaded |
| Gender | Female-Male |
| Keyway | Single |
| LED Indicator | None |
| Material - Cable Jacket | PVC |
| Material - Connector Body | TPE |
| Material - Contact | Brass |
| Material - Coupling Nut | Black Epoxy Coated Zinc |
| Material - Plating Mating | Gold |
| Net Weight | 1285.479/g |
| Orientation | Straight to Straight |
| Poles | 8 |
| Temperature Range - Operating | -20° to +105°C |
| Wire/Cable Type | STOOW |
| Wire Size (AWG) | 16 |

This document was generated on May 19, 2026