


103316-2 Product Details

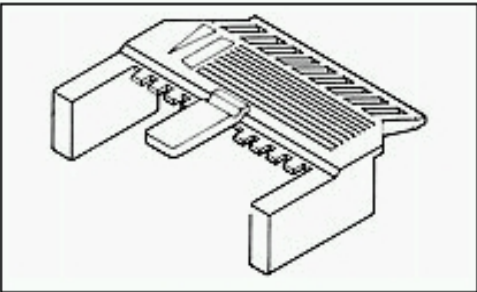

103316-2

TE Part Number: 103316-2

Active

Add to Part List

.100 AMPMODU Headers, Housings & Contacts

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Accessory
- Accessory Type = Cover
- Number of Positions = 10
- Cover Type = Ejection
- Cover Side = Front

View all Features | Find Similar Products

Live Product Chat

Quick Links

- Check Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product
- Request Samples

NEW!

Documentation & Additional Information

Product Drawings:

- COVER-HALF, LOW PROFILE, MASS TERMINATION, AMPMODU, ... (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- Connector, AMPMODU, Mass Terminated Standard Pressure (PDF, English)

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- Product Line Information

Related Products:

- Tooling

List all Documents

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Product Type = Accessory
- Accessory Type = Cover
- Number of Positions = 10
- Cover Type = Ejection
- Cover Side = Front
- Profile = Low
- Connector Series = MT
- Material = Thermoplastic
- Flame Retardant = Yes
- For Use With = Double Row Receptacle Assemblies
- Comment = This cover is to be used with 102536.; This cover compatible with eject header latches: PN 102186-1 with push tabs, PN 102320-1 without push tabs.

Body Related Features:

- Centerline, Matrix (mm [in]) = 2.54 [.100]

Industry Standards:

- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Other:

- Brand = AMP