

SEARCH KEYWORD, PART NUMBER 

Part Number: 15466325

Product Name: GT150 Series

4 Way F GT 150 Sealed

 
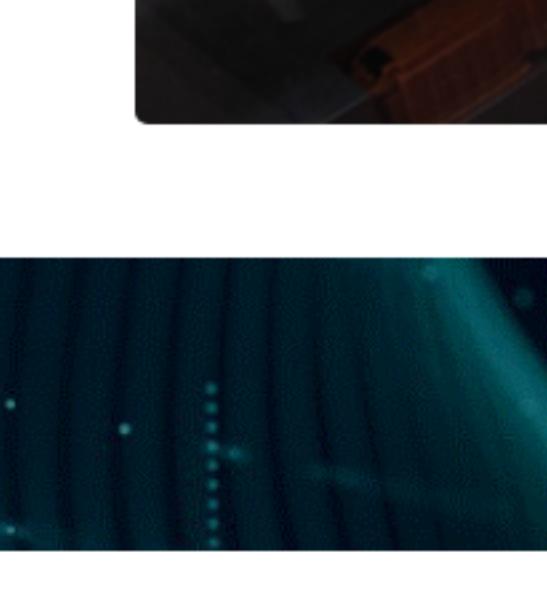
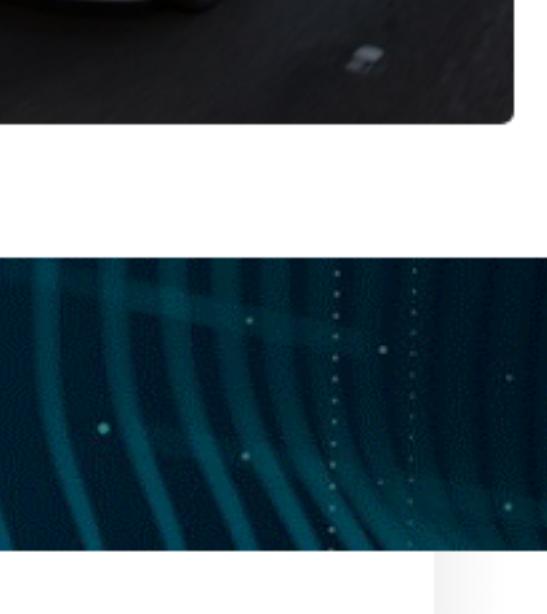
 
 Share  Print [Contact Us About This Item](#)[GET SAMPLES](#) 

ATTRIBUTES DOCUMENTS ECAD COMPATIBLE PARTS

 
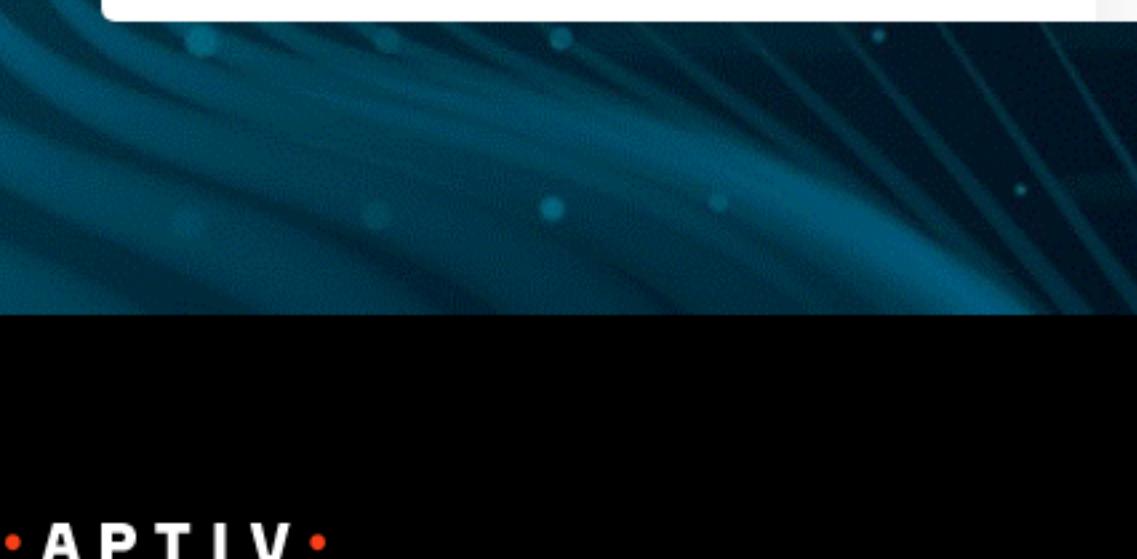
Attributes

Product Family	Height (mm)
GT	23.13
Product Series	Color
150 Series	BLACK
Max. operating temperature	Primary Locking Mechanism
+125°C	LOCKING LANCE
Min. operating temperature	Weight (g)
-40°C	9.72515
No. of Ways	Terminal 1 Size
4	1.5
Cable Exit Orientation	Sealing
180°	Sealed
Gender	Primary Material
Female	PBT GF 20
Length (mm)	Coding/Index
28.6	101
Width (mm)	
32.66	

Other Products

RESOURCE-CENTER-ITEM 35829171 35829170 35829169
COV CONN CLIP CDT BLACK 2 Way Male 0.5 Unsealed Green 2 Way Male 0.5 Unsealed Violet 2 Way Male 0.5 Unsealed Blue   

Next Steps



Keep pace with where mobility is going.

See what's next and get the latest [updates](#).[SIGN UP TO GET UPDATES](#) 

Don't worry. We won't flood your inbox or share your email.

