


## C8, Cast Bronze Ground Clamp, Cable to Water Pipe or Tube

By Burndy  
Catalog # [C8](#)

Cast Bronze Ground Clamp, Cable to Water Pipe or Copper  
Tube, 10 - 2 AWG, 4-1/2" - 6" Water Pipe.

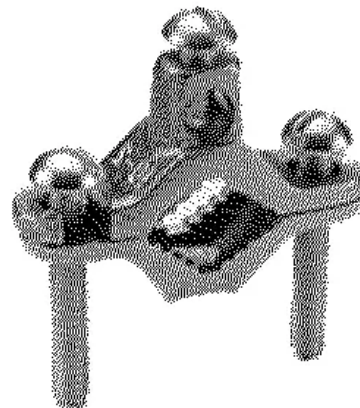

### Features

- Connects grounding conductor to water pipe or copper tube
- Supplied with Zinc-plated steel hardware

### Application

For Bare Wire, Connecting Grounding Conductor To Water Pipe  
Or Copper Tube

### General

Catalog Number	C8
EU RoHS Indicator	Yes
Material	Bronze Alloy
Material - Hardware	DURIUM™ Silicon Bronze
Sub Brand	CLAMP
Trade Name	N
Type	Ground Clamp
UPC	781810142332
UPC 14 Digit GTIN	00781810142332

### Dimensions

Dimension - Height inch	4.29 in
Dimension - Height mm	109 mm
Dimension - Hole Size inch	0.31 in
Dimension - Hole Size mm	8 mm
Dimension - Pad Width inch	1.88 in
Dimension - Thread Size	-
Dimension - Width inch	1.25 in
Dimension - Width mm	32 mm

### Conductor Related

Conductor - Armored Cable Size	N
-----------------------------------	---

Conductor - Copper Solid Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG
Conductor - Copper Solid Size Range	10 AWG-2 AWG
Conductor - Copper Str Size Range	10 AWG - 2 AWG
Conductor - Pipe EMT Size	4 in
Conductor - Pipe EMT Size Range	4 in
Conductor - Rebar Size Range	N/A

### Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - UL Listed Direct Burial	N
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

### Logistics

Carton Quantity	6
Minimum Pack Quantity	1

### Product Assets

[Catalogs - Burndy Grounding Catalog](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_CN\\_LineArt](#)  
[Sales Drawings - sc210654-01](#)  
[Specifications - C8](#)