


KS25, Split Bolt Connector, Run/Tap: #4 AWG-1/0 AWG Str

By Burndy
Catalog # [KS25](#)

Copper Split Bolt, Cu: 4 AWG-1/0 AWG (Str) (Run & Tap)

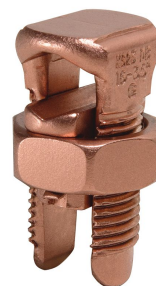

Features

- UL467 Listed for Direct Burial applications in earth or concrete
- Compact, high-strength, copper alloy with free-running threads and easy to grip wrench flats
- Highly resistant to cracking and corrosion

Application

For Direct Burial Applications In Earth Or Concrete, Copper

Specifications

Certification - UL Recognized	No
Buy American Compliant	Yes
Certification - cULus	No
EU RoHS Indicator	Yes
Buy America(n) Qualified	• Buy America Compliant (All status valid till December 2026) • Buy American Act Compliant (All status valid till December 2026) • BABA Compliant (All status valid till December 2026)
Industry Standard(s)	RUS
Certification - ETL	No
Standards - Industry Standards Met	RUS
Standards - RoHS Compliance Status	CM
Certification - UL Listed Direct Burial	Yes
UL Listed	Yes
Certification - CSA Approved	No

Conductor

Conductor - Copper Str Run Range	4 STR - 1/0 STR
Conductor - Copper Str Run	• 4 AWG • 3 AWG • 2 AWG • 1 AWG • 1/0
Conductor - Copper Solid Run Range	4 AWG-1/0
Conductor - Copper Solid Run	2/0 AWG

Conductor - Copper Solid Tap Range 14 AWG-1/0

Conductor - Copper Solid Tap 2/0 AWG

Conductor - CopperWeld Solid Tap Range 2/0

Conductor - CopperWeld Solid Tap 2/0

Conductor - CopperWeld Solid Run Range 2/0

Conductor - CopperWeld Solid Run 2/0

Conductor - CopperWeld Str Tap Range 5 D AWG-2 A AWG

Conductor - CopperWeld Str Tap

- 5 D AWG
- 5 P AWG
- 4 A AWG
- 4 D AWG
- 4 N AWG
- 4 P AWG
- 3 A AWG
- 3 J AWG
- 3 K AWG
- 3 N AWG
- 3 P AWG
- 2 A AWG

Conductor - CopperWeld Str Run Range 4 D AWG-2 A AWG

Conductor - CopperWeld Str Run

- 4 D AWG
- 4 N AWG
- 4 P AWG
- 3 A AWG
- 3 J AWG
- 3 K AWG
- 3 N AWG
- 3 P AWG
- 2 A AWG

Conductor Type

- CU C Solid-Run
- CU C Str-Run
- CU Weld C Solid-Run
- CU Weld C Str-Run
- CU C Str-Tap
- CU Weld C Solid-Tap
- CU Weld C Str-Tap
- CU C Solid-Tap

Conductor - Copper Str Tap Range 4 STR - 1/0 STR

Conductor - Copper Str Tap

- 14 AWG

- 12 AWG
- 10 AWG
- 9 AWG
- 8 AWG
- 7 AWG
- 6 AWG
- 5 AWG
- 4 AWG
- 3 AWG
- 2 AWG
- 1 AWG
- 1/0

Configuration

Connector Type Split Bolt

Dimensions

Package Height 0.000 in
Package Weight 0.000 lb.
Package Length 0.000 in
Package Width 0.000 in
Dimension - L Length Overall 45 mm
mm
Width 0.73 in
Dimension - Width fraction 73/100 in
Dimension - B Length fraction 83/100 in
Dimension - Width mm 19 mm
Dimension - Width inch 0.73 in

Dimension - B Length inch .83 in
Dimension - Cross Flats inch 0.94 in
Dimension - Length Overall 1.77
inch

Force Related

Installation Torque 385 in
Recommended in-lb

General

Trade Name SERVIT®
Plated N
Sub Brand SERVIT
UPC 781810013106
Type KS, Compact
Material Copper
Plating Type Unplated
UPC 12 Digit 781810013106
UPC 14 Digit GTIN 00781810013106

Logistics

Minimum Pack Quantity 50
Pallet Quantity 11600
Carton Quantity 50

Product Assets

[Catalog \[English\]](#)



A Hubbell brand