

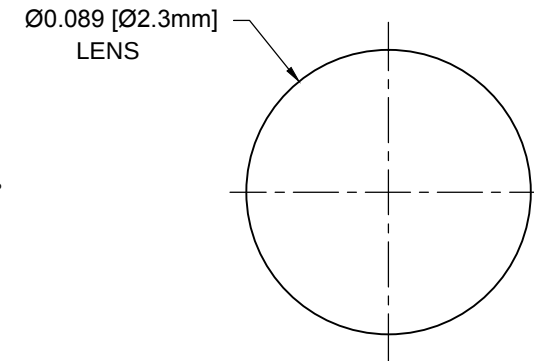
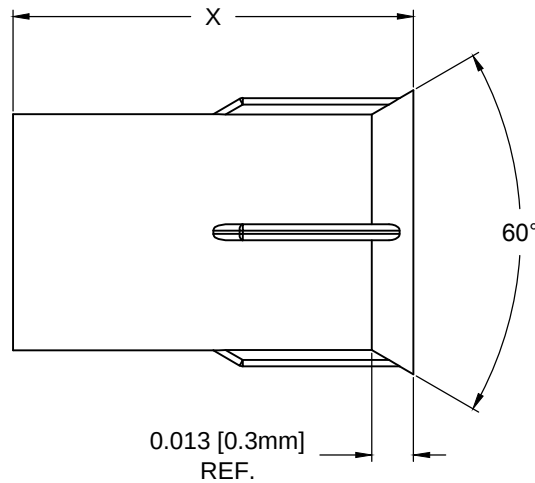
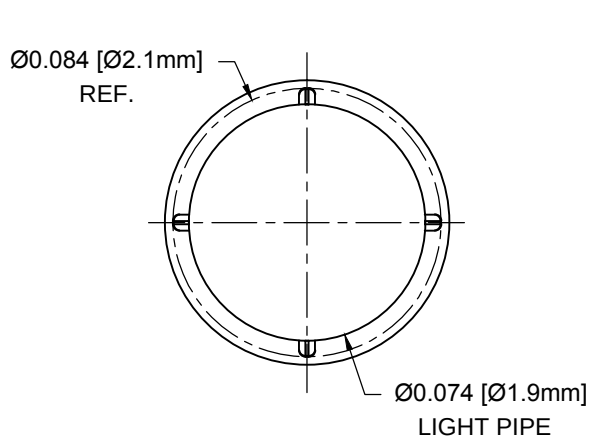


 
REV.	DESCRIPTION	DATE	APPROVED
B	Engineering Release	07/15/15	J. C.
C	Added Color Options, Sheet #2	01/25/16	J. C.
D	Revised Color Table, Sheet #2	07/02/18	G. O.

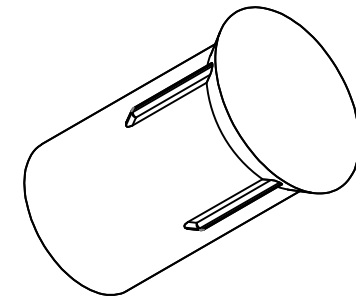

BODY LENGTHS FOR CLEAR LIGHT PIPES.

Part No.	X = Body Length
PLPC2-100	0.100 (2.5mm)
PLPC2-125	0.125 (3.2mm)
PLPC2-188	0.188 (4.8mm)
PLPC2-250	0.250 (6.4mm)
PLPC2-313	0.313 (7.9mm)
PLPC2-375	0.375 (9.5mm)
PLPC2-500	0.500 (12.7mm)
PLPC2-3MM	3mm (0.118")
PLPC2-4MM	4mm (0.157")
PLPC2-5MM	5mm (0.197")
PLPC2-6MM	6mm (0.236")
PLPC2-7MM	7mm (0.276")
PLPC2-8MM	8mm (0.315")
PLPC2-9MM	9mm (0.354")
PLPC2-10MM	10mm (0.394")

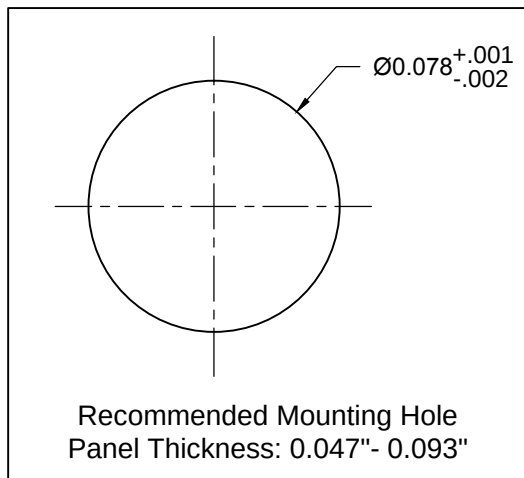

STANDARD TOLERANCE (UNLESS OTHERWISE SPECIFIED)		 BIVAR [®] 4 THOMAS, IRVINE, CA. 92618 TEL: (949) 951-8808 FAX: (949) 951-3974	
DECIMALS	ANGULAR		
.X ± .1	X° ± 1°		
.XX ± .01			
.XXX ± .005		TITLE: PRESS FIT, PANEL MOUNT LIGHT PIPE, FLUSH, 2mm	
DESIGNED: A. WRIGHT	DATE: 4/24/15	PART NO: PLPC2-XXX	REVISION: D
REVISED: TD. NGUYEN	DATE: 7/2/18	CAGE CODE: 32559	
CHECKED: K. BARON	DATE: 7/2/18	SCALE: NONE	SHEET # 1 OF 2
CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING			

2. MATERIAL: POLYCARBONATE, 94V-0, CLEAR.
1. GENERAL SPECIFICATIONS: BIVAR MOLDED COMPONENT SPECIFICATION BV00-E101 and BSMC-1001.

OTHER AVAILABLE COLORS
* SEE TABLE FOR ORDERING INFORMATION

REV.	DESCRIPTION	DATE	APPROVED
	SEE SHEET #1		

AVAILABLE COLOR OPTIONS

PLPC2 - _ _ _ 

RIGID LIGHT PIPE
SERIES

LENGTH

PART NUMBER	BODY LENGTH	COLOR	Order Code
PLPC2-100	0.100" (2.5mm)	TINTED BLUE	BE
PLPC2-125	0.125" (3.2mm)	TINTED GREEN	GN
PLPC2-2.5mm	2.5mm (0.100")	TINTED RED	RD
PLPC2-3mm	3mm (0.118")	TINTED YELLOW	YW

PLPC2 - _ _ _ - 

RIGID LIGHT PIPE
SERIES

LENGTH

PART NUMBER	BODY LENGTH	COLOR	Order Code
PLPC2-100	0.100" (2.5mm)	DIFFUSED	D
PLPC2-125	0.125" (3.2mm)	SMOKED	S
PLPC2-2.5mm	2.5mm (0.100")		
PLPC2-3mm	3mm (0.118")		



PART NO: PLPC2-XXX		REVISION: D
SCALE: NONE	SHEET # 2 OF 2	
CAD GENERATED DOCUMENT, DO NOT MEASURE DRAWING		