




WIRE AND CABLE

HOOK UP WIRE

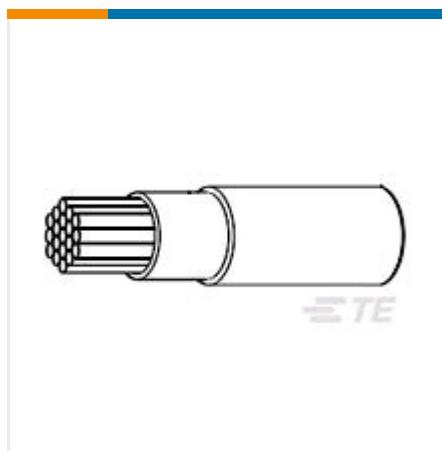

✓ Active

TE CONNECTIVITY (TE)

FLDWC0311-0.25-2

Raychem

FLDWC0311-0.25-2

TE Internal Number: 4766853004

Alias ID: 1-1193570-3

EU RoHS Compliant

EU ELV Compliant

Cable Type FlexLite DW

Voltage Rating (V) 600

Insulation Material Radiation-Crosslinked, Modified Polyalkene

Conductor Material Tin-Plated Copper

Wire Size (AWG) 30

PRODUCT DRAWING

English

DOCUMENTATION

Product Drawings

Customer Drawing

PDF

English

FEATURES

Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features



Cable Type FlexLite DW

Cable Style Primary, Stranded

Product Classification Wire - Commercial

Product Type Wire

Configuration Features

Number of Strands 19

Number of Conductors 1

Electrical Characteristics

Voltage Rating (V) 600

Resistance (Max) 83.6 Ω /1000 ft @ 68°F

Body Features

Insulation Material Radiation-Crosslinked, Modified Polyalkene

Conductor Material Tin-Plated Copper

Wire Color Red

Weight (kg/km) 3.77

Dimensions

Strand Size (AWG) 36

Wire Size (AWG) 30

Wire Size (mm²) .25

Conductor Diameter .59 mm [.024 in]

Insulation Thickness .127 mm [.005 in]

Overall Outside Diameter Range 1.12 – 1.22 mm [.044 – .048 in]

Overall Outside Diameter 2.73 mm [.1075 in]

Conductor Diameter Range .55 – .63 mm [.022 – .025 in]

Wire Diameter 1.169 mm [.046 in]

Conductor Size (mm²) .25

Usage Conditions

Operating Temperature Range (°C) -45 – 125

PRODUCT COMPLIANCE



Statement of Compliance

[Statement of Compliance](#)

PDF
