

 
Type: 011212090

External dimensions: 120 x 122 x 91 mm

Weight: 1170 g


DIN rail length in mm	max. fitting length in mm	Earthing rail clamp	Mounting plate (thickness in mm)	External mounting brackets	External hinge* set	EMC version	Internal hinge* set	SWB / SBGL / SBGL Corr.protection	Allen lid screws	Silicone lid seal	Sealable lid screws in steel	Turn bolt fastener on request	Quick lock
TS 35													
107	85	5	1.5	•	•	•		•	•	•	•		•

Maximum number of cable glands to DIN 50262*




M	Corner dim.	Side		PG	Corner dim.	Side	
		A	C			A	C
12	17.25	16	11	7	17.25	16	11
16	25.30	8	5	9	21.85	11	6
20	27.60	6	4	11	25.30	6	4
25	37.95	3	2	13.5	27.60	6	3
32	48.30	2	1	16	31.05	5	2
40	60.95			21	37.95	2	2
50	69.00			29	48.30	2	1
63	74.75			36	60.95		
				42	69.00		
				48	74.75		

Lid

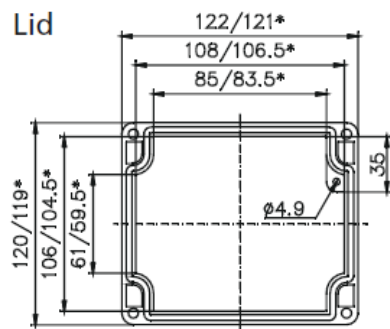


* = Conical form tapering downwards
Free dimensions-tolerance to GTA 13/5 DIN 1688

Cylinder screw
M6x25/10
similar to DIN 84

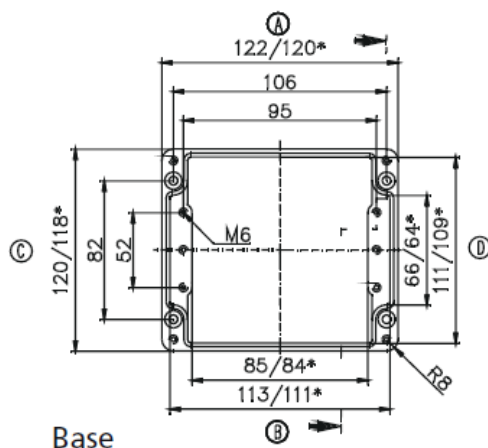

Base

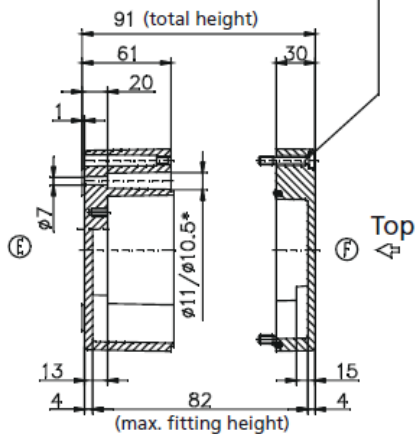

DATE		17 MAY 2017	7330 Executive Way Frederick, MD 21704 (301) 696-9411 voice (301) 696-9494 fax	
SHEET		1		
DESCRIPTION				
ENCLOSURE, STANDARD, ALUMINUM 120 X 122 X 91MM, RAL 7001				
SIZE	DRAWING NUMBER			REV
A	011212090			-