



Honeywell Sensing and Control



Search



2TP1-1
 (Home : Products : Switches » MICRO SWITCH™ Rocker Switches » Power-duty Rocker Switches » TP)

Products

- Controls Monitoring and Lighting (352)
- Machine Safety (1701)
- Sensors (6224)
- Switches (9749)
- Wireless (39)

Technology

- Control and Instrumentation (1052)
- Electromechanical (9301)
- Magnetic (541)
- Optical/Infrared (1042)
- Thick Film (1764)
- More...

new products

New Wireless Products

Go farther. Work smarter. Explore new possibilities. Just by cutting the cord and making the switch.



Wireless Web Site
 WGLA and WPMM
 XYR6000™


[find out more](#)

white papers

- Wireless Switches Offer Unlimited Benefit
- Basic Switches Are Not Created Equal
- Applying Precision Switches
- Sensors for Medical Devices
- New Ways to Measure Torque
- Choosing Safety Switches
- Specifying Hour Meters

Need help?

[Click here to contact us](#)

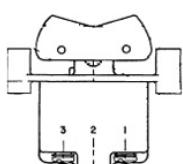

TP Series Rocker Switch, 2 pole, 3 position, Screw terminal, Flush Panel Mounting

Actual product appearance may vary.

[Sales & Service](#)

[Distributor Inventory](#)

[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Product Type	MICRO SWITCH™ Rocker		
Contact Type	Silver Cadmium Oxide Contacts		
Circuitry	DPDT		
Action	3 position		
Circuitry/Operating action	Keyway Position	Center Position	Opposite Keyway Position
	1 2 3	1 2 3	1 2 3
ON	6 5 4	6 5 4	6 5 4
	ON	OFF	ON
Mounting	Flush Panel		
Lamp Type	Translucent		
Termination	Screw		
Ampere/Voltage Range (Resistive Load)	0.75 A at 115 Vdc, 0.5 A to 10 A at 0.5 Vac to 277 Vac, 0.5 A to 15 A at 0.5 Vdc to 28 Vdc, 0.5 A at 250 Vdc		
LED/Lamp/Neon Voltage	L191: 15 A-125, 250, 277 Vac; 1/2 Hp-125 Vac; 1 Hp-250, 277 Vac; 5 A-120 Vac "L"		
Comment	Silver cadmium oxide contacts		
Availability	Global		
UNSPSC Code	302119		
UNSPSC Commodity	302119 Switches and controls and relays		
Series Name	TP		

contacts

- Customer Service
- Technical Support
- Global Sales & Service
- [View Site Demo](#)
- [Site Comments?](#)

meet dr. larry

VIDEO - Dr. Larry Goldstein explains our newest and best technologies.

[Meet Dr. Larry](#)



my links

- [Login to iCOM](#)
- [Login to Rep/AD Portal](#)
- [Login to Digital University](#)

News Center

- HONEYWELL ANNOUNCES ADDITION TO RELIALIGN™ RESIDENTIAL DOOR INTERLOCK SWITCHES THAT FEATURE RUGGED, PLASTIC HOUSING
- HONEYWELL RELEASES UNLIMITED POTENTIAL WITH NEW LIMITLESS™ WIRELESS SWITCHES
- HONEYWELL'S XYR6000 WIRELESS POSITION SENSOR ENABLES MONITORING IN HAZARDOUS AREAS AND REMOTE LOCATIONS

MICRO SWITCH Anniversary site