




Part Number : [734160010](#)

Product Description : DIN 7/16 Jack, Straight, 4-Hole
Flange Mount, One Piece Per Carton, 50 Ohms

Series Number : 73134

Status : Active

Product Category : RF / Coaxial Connectors

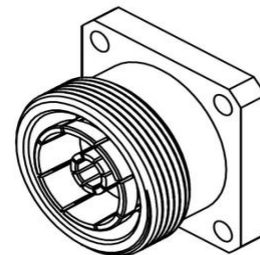

Documents & Resources

Drawings

[734160010_sd.pdf](#)

Specifications

[PS-89675-335-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2021)10043-DC (17 Jan 2022)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73134
Description	DIN 7/16 Jack, Straight, 4-Hole Flange Mount, One Piece Per Carton, 50 Ohms
Application	Telecommunications/Networking, RF
Product Name	7/16 DIN
Style	Panel
Type	Large
UPC	756054425978

Electrical

Frequency	7.5 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 2700 Vrms@Sea Level

Physical

Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	N/A
Net Weight	84.440/g
Orientation	Straight
Packaging Type	Individual Carton
Panel Mount	Yes
Panel Mount Method	Flange
PCB Mounting	N/A
Reverse Polar	No

Wire/Cable Type	N/A
-----------------	-----

This document was generated on Sep 18, 2025