


Series
BPX

SIZE 8 CONCENTRIQUE TWINAX SOCKET CONTACT
FOR MIL-C-17/176-00002 CABLE
AND RAYCHEM 10614-24-9 CABLE

Issue:
Dec. 09, 2010

Page
1/1

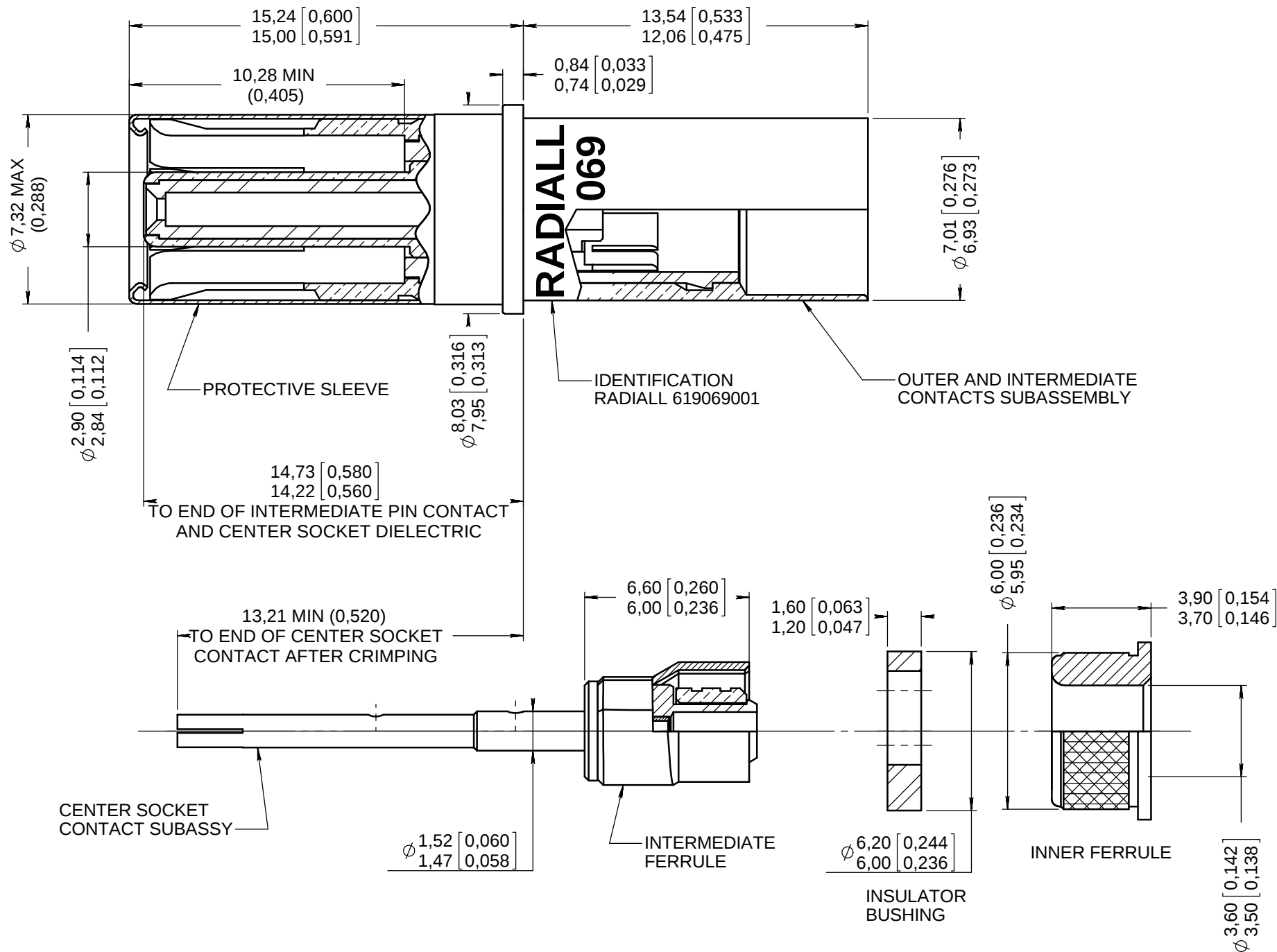

MATERIALS:

 
- OUTER AND CENTER CONTACT: BERYLLIUM COPPER ALLOY PER QQ-C-530 HEAT TREATED ANNEALED ON CRIMP BARREL
- INTERMEDIATE CONTACT: BERYLLIUM COPPER ALLOY PER QQ-C-530 HEAT TREATED
- FERRULE AND INNER FERRULE: BRASS PER QQ-B-626
- INTERMEDIATE DIELECTRIC AND INSULATOR BUSHING: PTFE
- CENTER DIELECTRIC: ULTEM
- PROTECTIVE SLEEVE: STAINLESS STEEL AISI305

FINISHES (ALL METAL PARTS)

- GOLD PER MIL-G-45204, TYPE II, GRADE C, CLASS 1 OVER NICKEL PER QQ- N-290, CLASS 2

WIRING INSTRUCTIONS: SEE RP08820

DIMENSIONS : mm (inch are given for information only)



4112_9311	CREATION				
	PEN: M000400011A				
	NOM: MACARI JP.	Dec. 09, 10	Spaces suppr. in the P/N : 619 069 001 => 619069001	Lalloz	Pessard
	DATE: Feb. 21, 2000	Dec. 12, 08	Added RAYCHEM 10614-24-9 cable	Legendre	Brochet
	APPR.: JACOB	Nov. 17, 03	Redrawn	Legendre	Macari
		Issue	Revisions	Name	Approved

619069001EN

RADIAL PROPRIETARY INFORMATION

This information is given as an indication. In the continual goal to improve our products, we reserve the right to make any modifications judged necessary.