

PRODUCTS

LAPP Katalog 2016 EN > Products > Catalogue > Tools and cable accessories > Connection and crimping > Conductor end sleeves > Conductor end sleeves insulated

PRODUCTS

Catalogue

Tools and cable accessories

Connection and crimping

Conductor end sleeves

Conductor end sleeves insulated

Deciband AHIB

Conductor end sleeves AHK, insulated

DIN-Coil conductor end sleeves

DIN-strips for QUADRO

TWIN conductor end sleeves

DIN-assorted boxes conductor end sleeves

AHI assorted boxes

TWIN assorted boxes

Conductor end sleeves XL, insulated

Conductor end sleeves AH, not insulated

Productfinder

Search brand competition

Inquiry form

Conductor end sleeves insulated


Conductor end sleeves with insulation for cabinet builders , according to DIN or German colour code, CSA approved, halogen-free

- product information (PDF)
- shipping and delivery




Suitable tools

Other customers also bought...

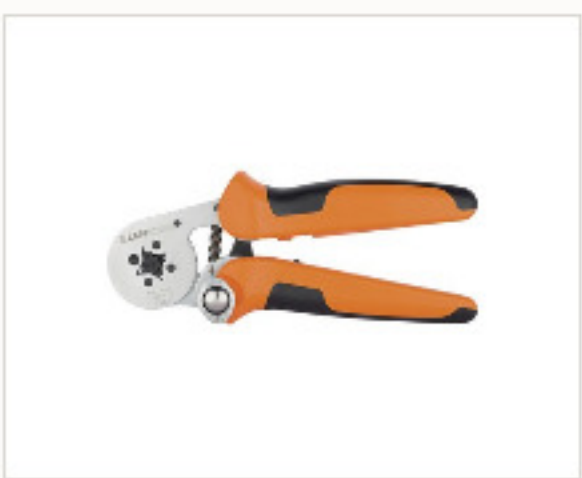

PEW 8.185 crimping pliers

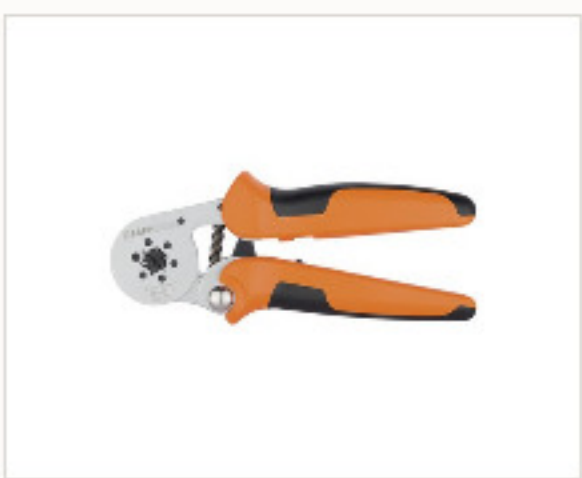

PEW 8.186 crimping pliers



PEW 8.87 crimping pliers



CK 90 crimping pliers

Article List

Product Description

Technical data

Note

Search

Q

Article number	Article designation	For mm²	AWG	Colour	l1 mm	l2 mm	d1 mm	s1 mm	d2 mm	s2 mm	
61721866	AHI N 0,25/6	0.25	24	light blue	10.5	6	0.8	0.25	1.8	0.25	
61721867	AHI L 0,25/8	0.25	24	light blue	12.5	8	0.8	0.25	1.8	0.25	
61721868	AHI N 0,34/6	0.34	24	turquoise	10.5	6	0.8	0.25	2	0.25	
61721869	AHI L 0,34/8	0.34	24	turquoise	12.5	8	0.8	0.25	2	0.25	
61801580	AHI DIN K 0.5/6	0.5	20	white	11.5	6	1.1	0.15	2.5	0.25	
61801590	AHI DIN N 0.5/8	0.5	20	white	13.5	8	1.1	0.15	2.5	0.25	
61801600	AHI DIN HL 0.5/10	0.5	20	white	15.5	10	1.1	0.15	2.5	0.25	
61721871	AHI N 0.5/8	0.5	20	orange	13.5	8	1.1	0.15	2.5	0.25	
61801620	AHI DIN K 0,75/6	0.75	20	grey	12	6	1.3	0.15	2.8	0.25	
61801630	AHI DIN N 0,75/8	0.75	20	grey	14	8	1.3	0.15	2.8	0.25	
61801640	AHI DIN HL 0,75/10	0.75	20	grey	16	10	1.3	0.15	2.8	0.25	
61801650	AHI DIN L 0,75/12	0.75	20	grey	18	12	1.3	0.15	2.8	0.25	
61721880	AHI N 0,75/8	0.75	20	white	14	8	1.3	0.15	2.8	0.25	
61801660	AHI DIN K 1/6	1	18	red	12.5	6	1.5	0.15	3	0.3	
61801670	AHI DIN N 1/8	1	18	red	14.5	8	1.5	0.15	3	0.3	
61801680	AHI DIN HL 1/10	1	18	red	16.5	10	1.5	0.15	3	0.3	
61801690	AHI DIN L 1/12	1	18	red	18.5	12	1.5	0.15	3	0.3	
61721890	AHI N 1/8	1	18	yellow	14.5	8	1.5	0.15	3	0.3	
61801700	AHI K 1.5/6	1.5	16	black	12.5	6	1.8	0.15	3.4	0.3	
61801710	AHI DIN N 1.5/8	1.5	16	black	14.5	8	1.8	0.15	3.4	0.3	
61801720	AHI DIN HL 1.5/10	1.5	16	black	16.5	10	1.8	0.15	3.4	0.3	
61801730	AHI DIN L 1.5/18	1.5	16	black	24.5	18	1.8	0.15	3.4	0.3	
61721900	AHI N 1.5/8	1.5	16	red	14.5	8	1.8	0.15	3.4	0.3	
61721910	AHI HL 1.5/10	1.5	16	red	16.5	10	1.8	0.15	3.4	0.3	
61746720	AHI L 1.5/18	1.5	16	red	24.5	18	1.8	0.15	3.4	0.3	
61801750	AHI DIN N 2.5/8	2.5	14	blue	15	8	2.3	0.15	4.2	0.3	
61801760	AHI DIN HL 2.5/12	2.5	14	blue	19	12	2.3	0.15	4.2	0.3	
61801770	AHI DIN L 2.5/18	2.5	14	blue	25	18	2.3	0.15	4.2	0.3	
61801780	AHI DIN N 4/10	4	12	grey	17.5	10	2.9	0.2	4.8	0.3	
61801790	AHI DIN HL 4/12	4	12	grey	20	12	2.9	0.2	4.8	0.3	
61801800	AHI DIN L 4/18	4	12	grey	26	18	2.9	0.2	4.8	0.3	
61801810	AHI DIN N 6/12	6	10	yellow	20	12	3.6	0.2	6.2	0.3	
61801820	AHI DIN L 6/18	6	10	yellow	25	18	3.6	0.2	6.2	0.3	
61721940	AHI N 6/12	6	10	black	20	12	3.6	0.2	6.2	0.3	
61721950	AHI L 6/18	6	10	black	26	18	3.6	0.2	6.2	0.3	
61801830	AHI DIN N 10/12	10	8	red	21	12	4.6	0.2	7.5	0.3	
61801840	AHI DIN L 10/18	10	8	red	27	18	4.6	0.2	7.5	0.3	
61721960	AHI N 10/12	10	8	ivory	21	12	4.6	0.2	7.5	0.3	
61721970	AHI L 10/18	10	8	ivory	27	18	4.6	0.2	7.5	0.3	
61801850	AHI DIN N 16/12	16	6	blue	23	12	6	0.2	8.8	0.4	
61801860	AHI DIN L 16/18	16	6	blue	29	18	6	0.2	8.8	0.4	
61721980	AHI N 16/12	16	6	green	23	12	6	0.2	8.8	0.4	
61721990	AHI L 16/18	16	6	green	29	18	6	0.2	8.8	0.4	
61801870	AHI DIN N 25/16	25	4	yellow	29	16	7.5	0.2	11	0.5	
61801890	AHI DIN L 25/22	25	4	yellow	35	22	7.5	0.2	11	0.5	
61746770	AHI N 25/16	25	4	brown	29	16	7.5	0.2	11	0.5	
61746780	AHI L 25/22	25	4	brown	35	22	7.5	0.2	11	0.5	
61801900	AHI DIN N 35/16	35	2	red	30	16	8.5	0.2	12.5	0.5	
61801920	AHI DIN L 35/25	35	2	red	39	25	8.5	0.2	12.5	0.5	
61746790	AHI N 35/16	35	2	beige	30	16	8.5	0.2	12.5	0.5	
61746800	AHI L 35/25	35	2	beige	39	25	8.5	0.2	12.5	0.5	
61801930	AHI DIN N 50/20	50	1	blue	36	20	10.5	0.3	15	0.6	
61801940	AHI DIN L 50/25	50	1	blue	41	25	10.5	0.3	15	0.6	
61801950	AHI N 70/20	70	2/0	yellow	37	20	13.5	0.4	16	0.6	
61801960	AHI L 70/27	70	2/0	yellow	44	27	12.7	0.4	16	0.6	
61801970	AHI N 95/25	95	3/0	red	44	25	14.7	0.4	18	0.6	
61801980	AHI N 120/27	120	4/0	blue	48	27	16.7	0.5	21	0.7	
61801990	AHI N 150/32	150	300	yellow	58	32	19.5	0.5	23	1	