


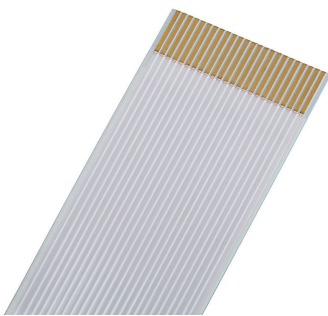

**Part Number :** [150200141](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 14 Circuits  
**Series Number :** 15020  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



Documents & Resources

**Drawings**  
[150200141\\_sd.pdf](#)

**Specifications**  
[PS-15020-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

## Part Details

### General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 14 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	884982176034

### Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

### Physical

Cable Length	51.00mm
Circuits (Loaded)	14
Contact Layout Type	A (same side)
Design Feature	Flexible
Material - Plating Mating	Gold
Net Weight	0.249/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

---

## Mates With / Use With

## Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 14 Circuits, Phosphor Bronze, Gold Plating	<u>5019511430</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 14 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<u>5019511450</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 14 Circuits, Gold over Nickel Plating	<u>5034801400</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 14 Circuits, Gold over Nickel Plating	<u>5051101492</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 14 Circuits, Gold Plating	<u>525591452</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 14 Circuits, Gold Plating	<u>527451497</u>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 14 Circuits, Gold Plating	<u>527461471</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Dual Contact Style, 1.20mm Mated Height, 14 Circuits, Gold (Au) Plating	<u>512811498</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 14 Circuits, Gold (Au) Plating	<u>545481472</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Top Contact Style, 14 Circuits, Gold (Au) Plating	<u>545501472</u>

0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 14 Circuits	<u>781191420</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 14 Circuits	<u>781271420</u>

---

This document was generated on Mar 15, 2025