


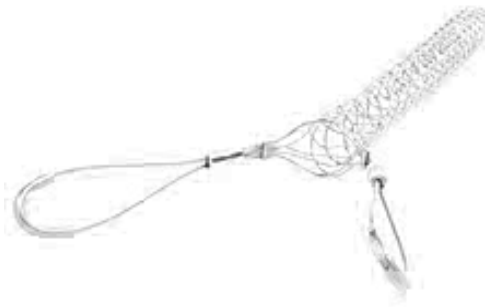

Part Number : [1300940211](#)
Product Description : Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 15.88-19.05mm (.625-.750"), Approximate Break Strength 521.63kg (1150 lbs)
Series Number : 130094
Status : Active
Product Category : Cable Grips
Engineering Number : 35002



Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Double Eye, Closed Mesh, Double Weave, Cable Diameter 15.88-19.05mm (.625-.750"), Approximate Break Strength 521.63kg (1150 lbs)
Product Name	Standard Duty
Type	Support Grip
UPC	78678835002

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	521.63kg (1150 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	15.88-19.05mm (.625-.750")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.279m (11.00")
Net Weight	574.330/g
Number of Holes	N/A

O-Ring	N/A
Thread Size	N/A

This document was generated on Sep 13, 2025