



Pushing Performance
Since 1945

Han RJ45 module, male for patch cords

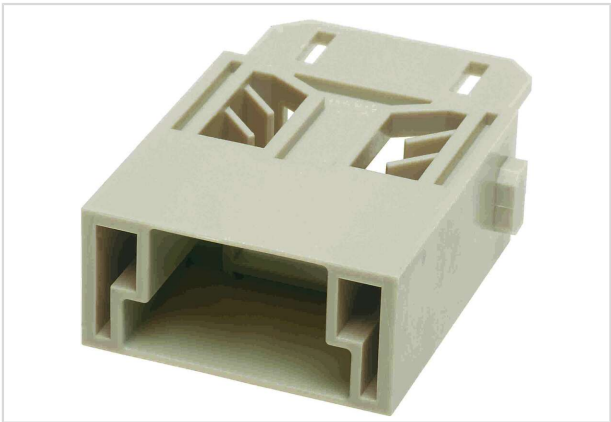


Image is for illustration purposes only. Please refer to product description.

Part number	09 14 001 4621
Specification	Han RJ45 module, male for patch cords
HARTING eCatalogue	https://harting.com/09140014621

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® RJ45 module
Size of the module	Single module
Description of the module	Single module for patch cable

Version

Gender	Male
Details	Please order patch cable separately.

Technical characteristics

Insulation resistance	$>10^{10} \Omega$
Limiting temperature	-40 ... +125 °C
Mating cycles	≥ 500

Material properties

Material (insert)	Polycarbonate (PC)
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance
Since 1945

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	7.24 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140019423
eCl@ss	27440207 Adapter for industrial connectors (module/contact insert)
ETIM	EC002312
UNSPSC 24.0	39121469