


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	50-00164	Connector, 4P mini DIN female, molding style, brass, nickel plating	1	
2	30-00024	Wire, 4C, 20 AWG, UL2464, 300 V, 80 C, 6.0 mm, shielded, VW-1, PVC, 79A	1	
3	24-00070	Overmold, jack, mini-DIN	1	black
4	Heat Shrink	Heat shrink tube, Ø 6.0, 105° C, L=10 ±2 mm	1	black
5	Heat Shrink	Heat shrink tube, Ø 1.0, 105° C, L=30 ±5 mm	1	black, covers drain wire
6	Tie	Twist tie	2	black

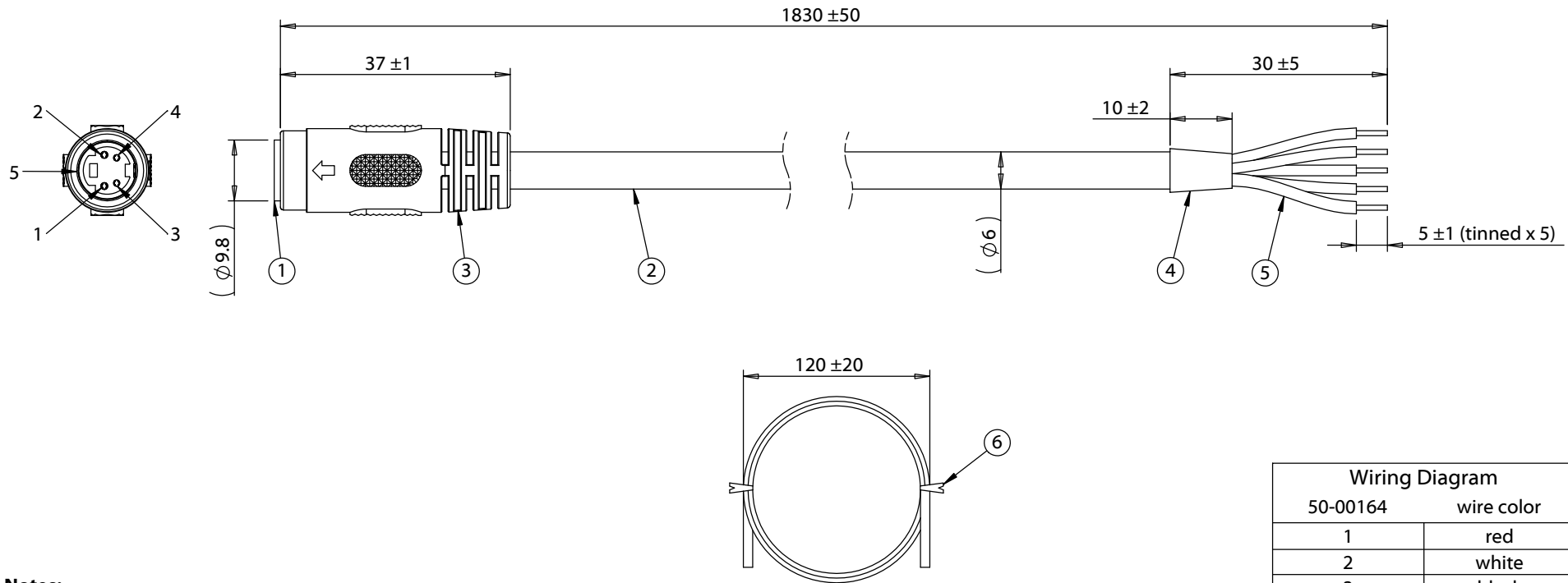

Notes:
Functionally equivalent components may be substituted

Electrical requirement: 2 A, 12 Vdc

Revision:	Date:	Description:	Prepared:	Notes:	TENSILITY tel 1.541.323.3228 800 877.670.7118 fax 1.541.323.4202 web tensility.com		
A	3/08/2011	Initial release	Verified:	RoHS and REACH compliant			
			Dimensions are in millimeters.	Function test: no open, no short circuit, no intermittent	Size: A Part number: 10-00427		
			Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Cable, 1830 mm, 4P mini-DIN female 50-00164, to stripped tinned, 20 AWG, UL2464 30-00024, shielded			
					Scale: 1:1		Sheet 1 of 1

5

↑

4

1

3

1

2

1

1