

# AMMA001010401R0MV1

Search by : [Part Number](#) [Characteristics](#) [Cross reference](#)




NEW ?

Closed Magnetic Circuit Type  
Molding Processing & for Ultra High Current

Series Pdf

| Product detail        |  |              |
|-----------------------|--|--------------|
| L(mm) ±               |  | 10±0.3       |
| W(mm) ±               |  | 11.5Max.     |
| T(mm) ±               |  | 4.0Max.      |
| Inductance(uH)        |  | 1            |
| Tolerance(±%)         |  | 20           |
| Test Frequency        |  | 100kHz,0.25V |
| RDC(Ω)Max             |  | 0.0041       |
| RDC(Ω)Typ             |  | 0.0037       |
| Isat(A)Typ            |  | 36           |
| Irms(A)Typ            |  | 17.5         |
| Operating Temperature |  | −55℃~125℃    |

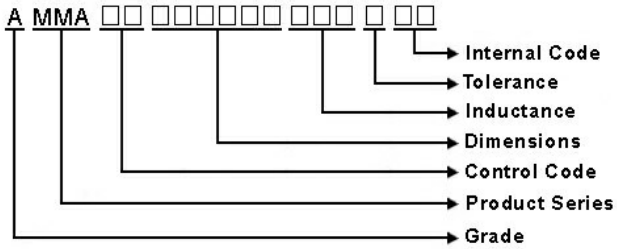

## Products

- Power Inductor
- EMI-Common Mode Choke
- EMI-Bead
- RF-Signal Inductor
- RF-Filter/Antennas
- RF-Wireless Power Transfer
- LAN Transformer
- Resistor & Current Sensor

## Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

## Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

## About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

## Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

## News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

## Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.