




Part Number : [731357240](#)

Product Description : Type F Straight Jack to MCX
Right-Angle Plug on RG-179 Cable, 127.00mm Length,
75 Ohms

Series Number : 73135

Status : Active

Product Category : RF Cable Assemblies

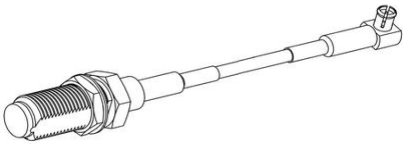

Documents & Resources

Drawings

[731357240_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF Cable Assemblies
Series	73135
Description	Type F Straight Jack to MCX Right-Angle Plug on RG-179 Cable, 127.00mm Length, 75 Ohms
Application	RF
Assembly Configuration	Dual Ended Connectors
Connector to Connector	F-to-MCX
Product Name	F,MCX
Type	RF Cable Assembly
UPC	191128196185

Electrical

Frequency	2 GHz
Impedance	75Ω

Physical

Cable Length	127.00mm
Gender	Jack/Plug
Material - Metal	Brass
Material - Plating Mating	Nickel, Gold
Material - Resin	PTFE
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	RG-179

Mates With / Use With

Mates with Part(s)

Description	Part Number
F Receptacles	<u>73330</u>

MCX Plugs and Jacks	<u>73366</u>
---------------------	--------------

This document was generated on Sep 10, 2025