

**Part Number :** [1300940370](#)


**Product Description :** Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs)

**Series Number :** 130094

**Status :** Active

**Product Category :** Cable Grips

**Engineering Part Number :** 35272

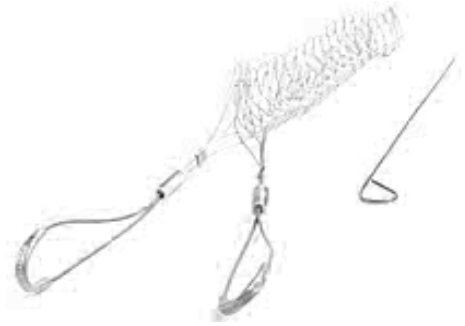

---

## Documents and Resources

### Drawings

[PK-130227-004-001.pdf](#)

---

## Product Environment Compliance

### Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### Substances of Interest

- PFAS

## Part Details

### General

Status	Active
Category	Cable Grips
Series	130094
Description	Standard Duty Support Grip, Double "U" Eye, Split Rod, Single Weave, Cable Diameter 19.05-25.15mm (.750-.990"), Approximate Break Strength 598.74kg (1320 lbs)
Product Name	Standard Duty
Type	Support Grip
UPC	78678835272

### Agency

CSA	LR32159
-----	---------

### Physical

Approximate Break Strength	598.74kg (1320 lbs)
Bale Length	0.102m (4.00")
Body Style	Straight
Cable Diameter	19.05-25.15mm (.750-.990")
Color - Grommet	N/A
Eye Type	Double
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.356m (14.00")
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A

This document was generated on Dec 16, 2025