

# LLA219R71C104MA01#

“#” indicates a package specification code.




## < List of part numbers with package codes >

LLA219R71C104MA01K

LLA219R71C104MA01L

## Appearance & Shape

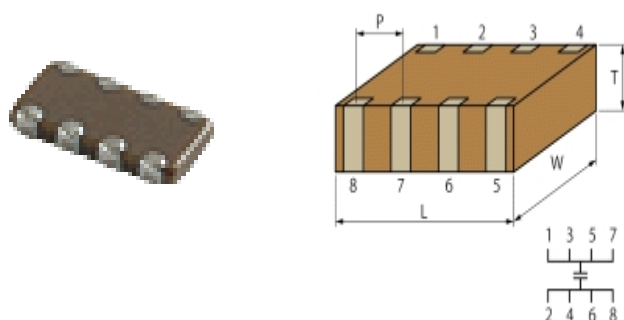

## References

Packaging	Specifications	Standard Packing Quantity
K	330Embossed Tape	10000
L	180Embossed Tape	3000

Mass (typ.)	
1 piece	11.0mg
φ180mm Reel	162g

### Attention


1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# LLA219R71C104MA01#

“#” indicates a package specification code.



## Specifications

Length	2.0±0.1mm
Width	1.25±0.1mm
Thickness	0.85±0.1mm
Capacitance	0.10μF ±20%
Distance between external terminals P	0.5±0.05mm
Operating Temperature Range	-55°C to 125°C
Rated Voltage	16Vdc
Size code in inch(mm)	0805 (2012M)
Capacitance change rate	±15.0%
Temperature characteristics (complied standard)	X7R(EIA)
Temperature range of temperature characteristics	-55°C to 125°C

### Attention

1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2.This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.