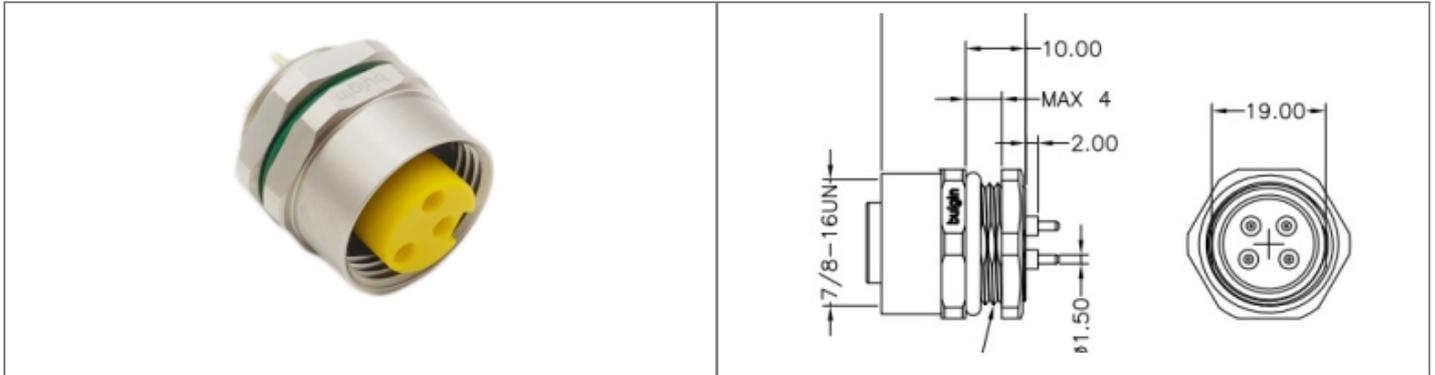


**Product Name // 3 Contacts 7/8" Front Panel Mounting
Female Connector**
 [View Product Page](#)

// Product Description:

-  3 Contacts 7-8" Front Panel Mounting Female Connector
-  IP67 rated when mated
-  Mechanical Cycles >100
-  Operating Temperature -25°C to +85°C
-  Rated Voltage 300 V
-  ROHS compliance

// General Information:

Product Display Title:	7/8" Flex Body Female Connector
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Connection Method:	PCB
Contact Pin Material:	Phosphor bronze gold plated 1u"
Contact Type:	Socket Contact
Current Max:	12A
Durability:	>100 Cycles
Function:	Front Panel Mounting Female Connector
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+85°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	4.0mm
Number Of Contacts:	3 Contacts
Panel Cut Out:	20.50mmx19.20mm
Pcb Thickness:	>2.5mm
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	PG13.5
Voltage Max:	300V

// Product PDF Links
 [78 Series Circular connectors...](#)
// Product 3D CAD Model Links
 [PXMBNI78FPF03APCPG1353D CAD Model](#)

 Have a question or project enquiry
you'd like to talk to us about?

[Click Here To Contact Us](#)