


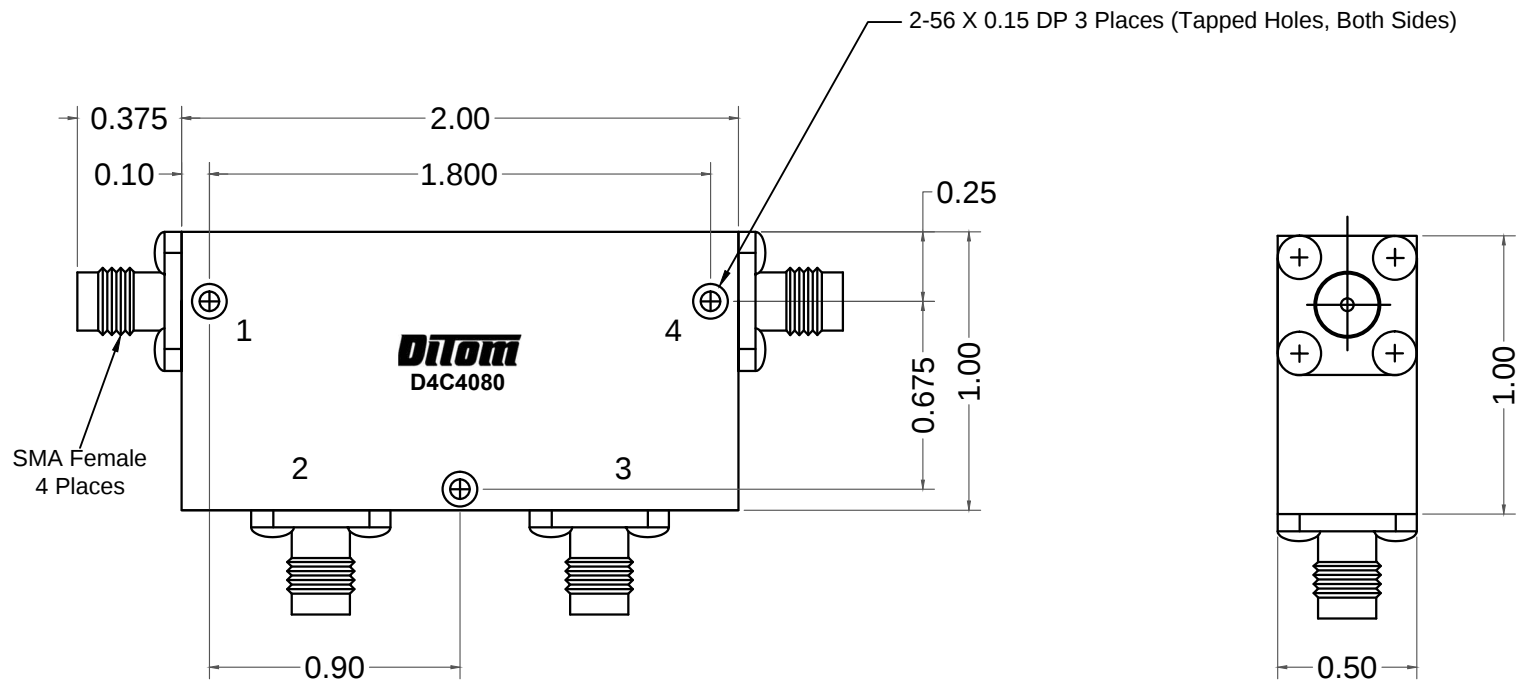

ELECTRICAL SPECIFICATIONS

FREQUENCY RANGE (GHz):	4.000 - 8.000
ISOLATION (dB):	20 MIN (PER JUNCTION)
INSERTION LOSS (dB):	0.40 MAX (PER JUNCTION)
VSWR:	1.25 MAX (PER JUNCTION)
POWER: AVG (ALL PORTS):	20W
PEAK:	30W

MECHANICAL SPECIFICATIONS

CONNECTORS:	SMA-FEMALE, STAINLESS STEEL, PASSIVATE
CONTACT PINS:	BERYLLIUM COPPER, GOLD PLATE
OPERATING TEMPERATURE:	-10° to +60°C
WEIGHT (APPROX):	2.30 OUNCES

DIMENSIONS IN INCHES, UNLESS OTHERWISE SPECIFIED		 Fresno, California, USA	
TOLERANCE XX±0.03 XXX±0.010	TITLE 4.0 - 8.0GHz SMA Circulator		
SCALE 3:1	MODEL NO D4C4080		REV