




Quality Products. Service Excellence.

Equipment Rack Cabinet *REFK Series*

Load rated to 1,000 lbs (454 kg)

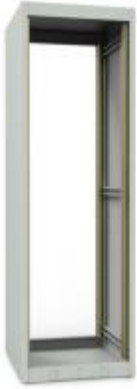

Features

- C-channel struts provide cabinet strength, ease, and flexibility to adjust mounting rails.
- Solid non-removable side panels.
- Optional flush-mounted doors with quarter-turn locks can be mounted to swing on either side.
- Self-squaring design ships un-assembled (some assembly required).
- Simple assembly using one bolt in each corner to lock the sides to the top and bottom.

Specifications

- The cabinet frame is constructed in 16-gauge steel.
- Includes two (2) pairs of adjustable depth 10-32 threaded EIA-compliant **combination rails**. Constructed in 10-gauge steel, include rack unit indicators, and are Zinc-plated to provide superior surface areas for equipment grounding.
- Includes four (4) leveling feet.
- Removable gland plate - over 10" (254 mm) long x 1.5" (38 mm) high opening - with knockouts on the rear bottom of the rack for easy cable access.
- 1,000 lbs (454 kg) **static load rating**.
- Finished in textured RAL 9005 black or RAL 7035 light gray powder coat. Complies with the Greenguard guidelines for indoor air quality.
- TAA-compliant for federal GSA schedule purchases within the USA.
- RoHS Compliant.
- Manufactured in North America within an ISO 9001:2015 certified facility.

Accessories

- Rack Shelves
- We Manufacture PDUs and Outlet Strips
- Horizontal Lacing Strip
- Cable Management Arm
- Bonding and Grounding
- Mounting Rack Rails
- Rack and Cabinet Caster Set
- Rack Shelf Slide Block
- 10-32 Mounting Hardware
- Adjustable Depth Front-To-Rear Cable Manager
- Horizontal Steel Finger Cable Manager
- Rack Panels
- Ground Stud Kit
- Square Hole Punched Mounting Rail
- Rack Equipment Installation Tool

REFK Active Sizes

Part No. RAL 9005 Black	Part No. RAL 7035 Light Gray	Overall Dimensions			Rack Units	Usable Mounting Dimensions		
		Height	Width	Depth		Height	Depth	Depth (With Doors)
REFK1903524BK1	REFK1903524LG1	40.19	21.34	24.50	20U	35.19	23.50	23.00
REFK1904224BK1	REFK1904224LG1	47.19	21.34	24.50	24U	42.19	23.50	23.00
REFK1905624BK1	REFK1905624LG1	61.19	21.34	24.50	32U	56.19	23.50	23.00
REFK1906324BK1	REFK1906324LG1	68.19	21.34	24.50	36U	63.19	23.50	23.00
REFK1907024BK1	REFK1907024LG1	75.19	21.34	24.50	40U	70.19	23.50	23.00

Part No.	Part No.	Usable Mounting Dimensions						
RAL 9005	RAL 7035	Overall Dimensions			Rack	Depth		
Black	Light Gray	Height	Width	Depth	Units	Height	Depth	(With Doors)
REFK1903531BK1	REFK1903531LG1	40.19	21.34	31.50	20U	35.19	28.50	28.00
REFK1904231BK1	REFK1904231LG1	47.19	21.34	31.50	24U	42.19	28.50	28.00
REFK1906331BK1	REFK1906331LG1	68.19	21.34	31.50	36U	63.19	28.50	28.00
REFK1907031BK1	REFK1907031LG1	75.19	21.34	31.50	40U	70.19	28.50	28.00

REFK Clearance

Part No.		Usable Mounting Dimensions						
RAL 9005		Overall Dimensions			Rack	Depth		
Black	Qty	Height	Width	Depth	Units	Height	Depth	(With Doors)
REFK1903517BK1	2	40.19	21.34	17.50	20U	35.19	16.50	16.00
REFK1907717BK1	4	82.19	21.34	17.50	44U	77.19	16.50	16.00

As of Feb 24, 2025

REFK Locking Doors

Solid Door		Solid Door		Louvered Door		Louvered Door		Window Door	
Part No. Black	Part No. RAL 7035 Light Gray	Part No. Black	Part No. RAL 7035 Light Gray	Part No. Black	Part No. RAL 7035 Light Gray	Part No. Black	Part No. RAL 7035 Light Gray	Use With REFK Frame	
								Height	Part No.
RSDf19035BK1	RSDf19035LG1	RSDL19035BK1	RSDL19035LG1	REDfP19035BK1	REDfP19035LG1	REDfP19035BK1	REDfP19035LG1	35.00	REFK19035XX
RSDf19042BK1	RSDf19042LG1	RSDL19042BK1	RSDL19042LG1	REDfP19042BK1	REDfP19042LG1	REDfP19042BK1	REDfP19042LG1	42.00	REFK19042XX
RSDf19049BK1	RSDf19049LG1	RSDL19049BK1	RSDL19049LG1	REDfP19049BK1	REDfP19049LG1	REDfP19049BK1	REDfP19049LG1	49.00	REFK19049XX
RSDf19056BK1	RSDf19056LG1	RSDL19056BK1	RSDL19056LG1	REDfP19056BK1	REDfP19056LG1	REDfP19056BK1	REDfP19056LG1	56.00	REFK19056XX
RSDf19063BK1	RSDf19063LG1	RSDL19063BK1	RSDL19063LG1	REDfP19063BK1	REDfP19063LG1	REDfP19063BK1	REDfP19063LG1	63.00	REFK19063XX
RSDf19070BK1	RSDf19070LG1	RSDL19070BK1	RSDL19070LG1	REDfP19070BK1	REDfP19070LG1	REDfP19070BK1	REDfP19070LG1	70.00	REFK19070XX
-	-	RSDL19077BK1	RSDL19077LG1	-	-	-	-	77.00	REFK19077XX

Optional Casters

Part No.	Strength	Style/ Material	Overall Height				Caster Set	Qty	Qty with
			Wheel	Added	Hole Mounting Pattern		Weight	Included	Brakes
			Diameter	to Cabinet	Width	Depth	Capacity	In Set	Included
1425BLSOFT	Light Duty	Soft Thermoplastic	2.95	3.50	1.75	3.00	660 lbs (299 kg)	4	4
1425BM	Medium Duty	Hard Composition	3.00	3.81	1.75	3.00	700 lbs (318 kg)	4	0
1425BH	Heavy Duty	Hard Composition	3.00	3.81	1.75	3.00	1,050 lbs (476 kg)	4	0
1425BHLOCK	Heavy Duty	Hard Composition	3.00	3.81	1.75	3.00	1,050 lbs (476 kg)	4	4

Tags: knock-down, knock down

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.