

BSCH001608081N0S00

Search by :

Part Number

Characteristics

Cross reference



MP

Multilayer-STD

Series Pdf

RoHSREACHCoC

Product detail

L (mm) ±	1.6±0.15
----------	----------

W(mm) ±	0.8±0.15
---------	----------

T (mm) ±	0.8±0.15
----------	----------

Size Code (JIS/EIA)	1608/0603
---------------------	-----------

Inductance(nH)	1
----------------	---

Tolerance(±%)	0.3nH
---------------	-------

Test Frequency(L)	100 MHz,200 mV
-------------------	----------------


Q Min	8
-------	---

Test Frequency(Q)	100 MHz,200 mV
-------------------	----------------

SRF(MHz)Typ	10000
-------------	-------

RDC(Ω)Max	0.1
-----------	-----

Product Status	600
----------------	-----

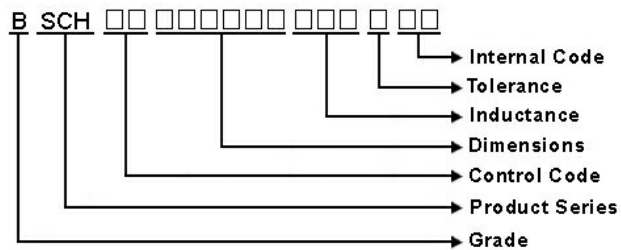

Products

- Power Inductor
- EMI-Noise Suppression
- RF-Signal Inductor
- Resistor & Current Sensor

Applications

- Automotive
- Industrial
- Server/DataCenter
- Communication
- Mobile and Tablet
- Computer/Laptop
- Consumer

Design Tools

- Simulation Tool
- Product Search Engine
- E-Catalogue

About Us

- Corporate Overview
- Corporate Milestones
- Core Technology
- Certificates & Awards
- Quality and Social Responsibility

Investor

- Financial Information
- Corporate governance
- Stakeholder Contacts

News

[Media Center](#)

[New Products](#)

[Events](#)

[Product Notices](#)

Contact Us

[Contact Info](#)

[Contact Form](#)

[Join Chilisin](#)

[Terms of Use](#)

[Privacy policy](#)

[Sitemap](#)



Inductor



Resistor



Powder

Copyrights © 2018. Chilisin. All rights reserved.