

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Sleeve housing B10, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, height: 57 mm, cable gland: none, support sleeve: no, 1x M25, Standard

Your advantages

- ✓ good shielding in the event of electromagnetic interference



Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 059525
GTIN	4055626059525
Weight per Piece (excluding packing)	160.000 g
Custom tariff number	85389099
Country of origin	Poland

Technical data

Dimensions

Height	57 mm
Width	44 mm
Length	73 mm

Ambient conditions

Degree of protection (IP)	IP66
	IP67
Degree of protection (NEMA)	4 (UL 50e)
	4X (UL 50e)

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Technical data

Ambient conditions

	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General


Note	For contact inserts HC-B10, BB18, DD42, M, K8/24
Size	B10
Housing type	Sleeve housing
Color	gray aluminum
Locking type	for single locking latch
No. of cable outlets	1
Cable outlet	lateral
Screw connection	none
Type of the screw connection	1x M25
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

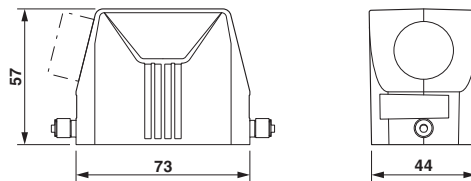

Dimensional drawing

Classifications

eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Classifications

eCl@ss

eCl@ss 9.0	27440202
------------	----------

ETIM

ETIM 6.0	EC000437
ETIM 7.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Approvals

Approvals

Approvals


UL Recognized / cUL Recognized / EAC / DNV GL / EAC / cULus Recognized

Ex Approvals

Approval details




UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
---------------	---	---	---------

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
----------------	---	---	---------

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Approvals

DNV GL		https://approvalfinder.dnvgl.com/	TAE000037S
EAC			RU C- DE.BL08.B.00511
cULus Recognized			

Accessories

Accessories

Corrugated pipe screw connection

Screw connection - WP-G HF IP66 M25 BK - 3240899



Cable gland, metric thread, IP66 protection, straight

Screw connection - WP-G HF IP69K M25 BK - 3240885



Cable gland, metric thread, IP68/69k protection, straight

Screw connection - WP-GA HF IP66 M25 BK - 3240927



Cable gland, metric thread, IP66 protection, angled

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Accessories

Screw connection - WP-GA HF IP69K M25 BK - 3240913



Cable gland, metric thread, IP68/69k protection, angled

Screw connection - WP-GR HF IP66 M25 BK - 3240955



Cable gland, metric thread, IP66 protection, with strain relief

Screw connection - WP-GR HF IP69K M25 BK - 3240941



Cable gland, metric thread, IP68/69k protection, with strain relief

Screw connection - WP-G PP HF M25 - 3240999



Cable gland made from PP with metric thread, IP65 protection

Screw connection - WP-GT PP HF M25 - 3241013



Cable gland made from PP with metric thread, rotatable, IP54 protection

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Accessories

Screw connection - WP-G BRASS IP40 M25 - 3241048



Cable gland made from brass with metric thread, IP40 protection

Screw connection - WP-GT BRASS M25 - 3241034



Cable gland made from brass with metric thread, rotatable, IP40 protection

Screw connection - WP-G BRASS IP65 M25 - 3241062



Cable gland made from brass with metric thread, IP65 protection

Full screw connection

Cable gland - G-INS-M25-M68N-NNES-S - 1411165



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 11 mm ... 17 mm, shielding: no, connecting thread: M25 x 1.5, color: silver, with O-ring

Cable gland - G-INSEC-M25-S68N-NCRS-S - 1411190



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 11 mm ... 16 mm, shielding: yes, connecting thread: M25 x 1.5, color: silver, with O-ring

Housing - HC-STA-B10-HLFS-1STM25-EL-AL - 1412625

Accessories

Cable gland - HC-M-KV-M25(1ASI) - 1584020



Metal screw connection for an AS-Interface flat-ribbon conductor, thread type M25

Labeled device marker

Plastic label - US-EMLP (20X9) CUS - 0830085



Plastic label, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, lettering field size: 20 x 9 mm, Number of individual labels: 75

Multiple screw connection

Cable gland - HC-M-KV-M25(1X10/1X11) - 1580228



Special cable screw connection M25, brass nickel-plated, grommet with 10 mm and 11 mm holes

Protective cover

Protective covers - HC-B10-HCLWS-PLR-BK - 1414635



Protective cover B10, with single locking latch, protective cover material: PA, height: 21.6 mm, seal: yes, diameter of retaining cord eyelet: 30 mm