


Extended length is with 500g of force

Materials:

- Plug Housing: Polycarbonate, clear
- Plug Terminal: 0.36"[.014MM] Thick Phosphor Bronze
- Connector: 50µ" of Selective Gold Contact Plating
 - Area, Gold flash over the remainder
 - Over 2.54µm[.000100] thick nickel underplate
- Conductor(X4C): 26AWG (0.12X12) Bare Copper
- Insulation(X4C): PP6331 ID 0.95-1.0
- Jacket: PVC NOUL 80P
- Package: Individual PE Bag

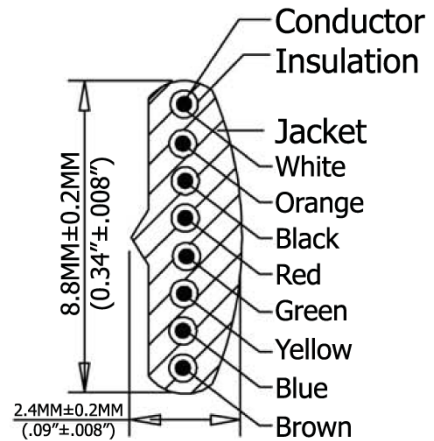

| P1 | | P2 |
|----|--------|----|
| 1 | WHITE | 8 |
| 2 | ORANGE | 7 |
| 3 | BLACK | 6 |
| 4 | RED | 5 |
| 5 | GREEN | 4 |
| 6 | YELLOW | 3 |
| 7 | BLUE | 2 |
| 8 | BROWN | 1 |

| Extended Length ("L2") | Typical Retracted Length ("L1") |
|-----------------------------|---------------------------------|
| 144.0 Inches - 165.6 Inches | 65.0 Inches |
| 3,657.6MM-4,206.24MM | 1,651.0MM |

SEC: A=A



ITEM NO
AT-C-26-8/8/W-12
 TITLE NON-UL 26AWG (0.16/7)*8C, O.D.: 2.4*8.8MM
 Standard Plug, 50µ" of contact plating, WHITE

ASSMANN
 Electronics, Inc.
 1840 W. Drake Drive, Suite 101 - Tempe, AZ 85283
 Toll Free: 1-877-277-6266 Email: info@usa-assmann.com

THIS DRAWING IS UNPUBLISHED
 © Copyright 2009 by Assmann Electronic Components
 All International Rights Reserved