



Enter Part Number:

Enter Keyword:

[Home](#) > [Products](#) > [NAND Flash](#) > [NAND Flash Part Catalog](#) > MT29F2G16ABDHC -ET

2Gb Mass Storage : MT29F2G16ABDHC-ET

[Print this page](#)

Overview

Resources & Support

[RSS part feed:](#)

Resources

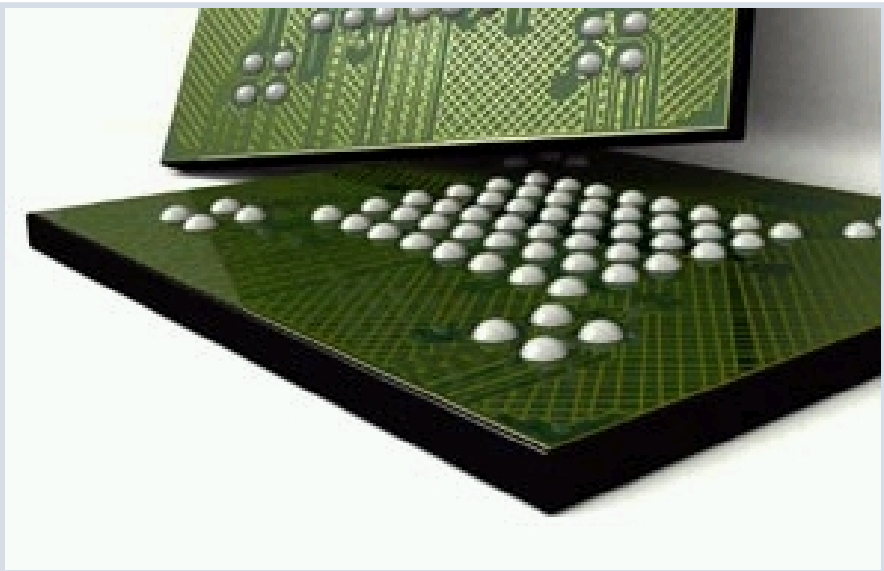


Illustration only. See data sheet for product specifications.

SPECIFICATIONS

Density: 2Gb
Part Status: Production
RoHS:Yes
Depth: 128Mb
Width: x16
Voltage: 1.8V
Package: VFBGA
Pin Count: 63-ball
I/O: Common
Op. Temp.: -40C to +85C

DESCRIPTION

Micron NAND Flash uses an industry proven floating gate cell and a standard interface to enable pin and function drop-in compatibility and easy integration into most existing designs.

RoHS-Compliant: This part meets internationally recognized Pbfree standards, including RoHS.

[RoHS Certificate of Compliance](#)
[China RoHS Certificate](#)

Orderable Part	Part Status	Buy Samples	Distributor Stock
MT29F2G16ABDHC-ET:D	Production	Contact Rep	Contact Rep

Please note: Distributor inventory is an estimate and may not reflect actual available inventory.

Some links on this page will take you from the Micron Web site. Micron does not control the content on these Web sites.