




Part Number : [528082971](#)

Product Description : Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 29 Circuits

Series Number : 52808

Status : Active

Product Category : FFC / FPC Connectors

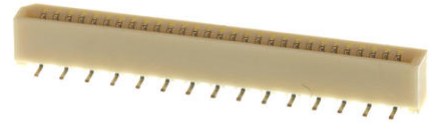

Documents and Resources

Drawings

[528082971_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)


Specifications

[528089200-200.pdf](#)

[PS-52808-004-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|---|
| GADSL/IMDS | Compliant with Exemption 33; 44 |
| China RoHS |  per SJ/T 11365-2006 |
| EU ELV | Not Relevant |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2025)7771-DC (04 Feb 2026) |
| EU RoHS | Compliant per EU 2015/863 |

[Compliance Statements](#)

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | FFC / FPC Connectors |
| Series | 52808 |
| Description | Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 29 Circuits |
| Product Name | Easy-On |
| UPC | 822348136391 |

Agency

| | |
|----|--------|
| UL | E29179 |
|----|--------|

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 0.5A |
| Voltage - Maximum | 125V |

Physical

| | |
|-------------------|---------|
| Actuator Type | Non-ZIF |
| Circuits (Loaded) | 29 |

| | |
|--------------------------------|--------------------------------|
| Color - Resin | Natural |
| Contact Position | N/A |
| Durability (mating cycles max) | 10 |
| Mated Height | 5.05mm |
| Material - Metal | Phosphor Bronze |
| Material - Plating Mating | Tin-Bismuth |
| Material - Plating Termination | Tin-Bismuth |
| Material - Resin | High Temperature Thermoplastic |
| Net Weight | 714.800/mg |
| Orientation | Vertical |
| Packaging Type | Embossed Tape on Reel |
| PCB Locator | No |
| PCB Mounting | Surface Mount |
| PCB Retention | No |
| Pitch - Mating Interface | 1.00mm |
| Pitch - Termination Interface | 1.00mm |
| Polarized to PCB | No |
| Stackable | No |
| Temperature Range - Operating | -20° to +80°C |
| Wire/Cable Type | FFC/FPC |

Mates With / Use With

Mates with Part(s)

| Description | Part Number |
|-------------------------------------|--------------|
| 1.00mm Pitch Premo-Flex FFC Jumpers | <u>15167</u> |
| 1.00mm Pitch Premo-Flex FFC Jumpers | <u>15267</u> |
| 1.00mm Pitch Premo-Flex FFC Jumpers | <u>98267</u> |

This document was generated on Apr 28, 2026