


YOUR SELECTED PRODUCT

For other versions than the listed available standard types, please contact PRECI-DIP

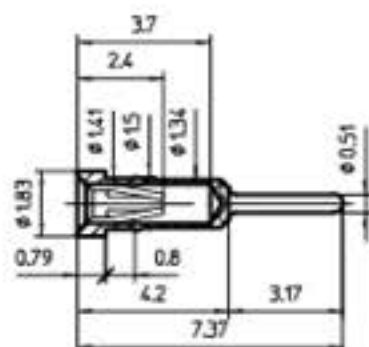

SPECIFICATIONS:

Socket contact with solder tail

- Press-in mount into dia 1.45 mm hole
- Materials: body brass, contact clip BeCu
- Electrical contact resistance max. 15 milliohms
- Mechanical life min. 500 cycles

AVAILABLE STANDARD TYPES

Ordering Part Number		Plating Body	Plating Clip	Insertion	Extraction	Dia. Gauge	Max Current
01001-13-3010	RoHS	0.25µm Au	0.75µm Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-77-3010	RoHS	Flash Au	Flash Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-83-3010	RoHS	5µm Sn	0.75µm Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-87-3010	RoHS	5µm Sn	Flash Au	2.00 N	1.00 N	0.43 mm	3.0 A
01001-83-3110	RoHS	5µm Sn	0.75µm Au	0.70 N	0.40 N	0.46 mm	3.0 A
01001-87-3110	RoHS	5µm Sn	Flash Au	0.70 N	0.40 N	0.46 mm	3.0 A
01001-83-3130	RoHS	5µm Sn	0.75µm Au	0.35 N	0.20 N	0.46 mm	3.0 A
01001-93-5210		5µm SnPb	0.75µm Au	1.50 N	0.80 N	0.78 mm	4.5 A

<< Back

[April 2012] PRECI-DIP Presents
Mateleco
More >>

[February 2012] Welcome to Mr
Raymond Kerrison, new
General Manager
..

swiss world connects

PRINT

SITEMAP

HOME

copyright © PRECI-DIP 2007

Powered by IviMedia