




Part Number : [734155230](#)

Product Description : MCX Jack, Straight, Bulkhead, Crimp, RG-174, RG-188 and RG-316 Cable, Brass Body, Nickel (Ni) Plated, 50 Ohms

Series Number : 73366

Status : Active

Product Category : RF / Coaxial Connectors

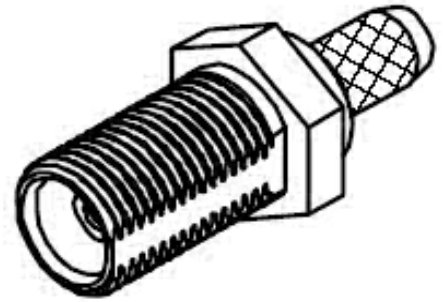

Documents and Resources

Drawings

[734155230 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[735970710-000.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D

- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73366
Description	MCX Jack, Straight, Bulkhead, Crimp, RG-174, RG-188 and RG-316 Cable, Brass Body, Nickel (Ni) Plated, 50 Ohms
Application	RF
Product Name	MCX
Style	Cable
Type	Microminiature
UPC	822348754908

Electrical

Frequency	6 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 335 Vrms@Sea Level

Physical

Cable Attachment	Crimp
Gender	Jack
Keying to Mating Part	N/A
Orientation	Straight
Packaging Type	Bag
Panel Mount	Yes
Panel Mount Method	Bulkhead

PCB Mounting	N/A
Reverse Polar	No
Wire/Cable Type	LMR-100, RG-174, RG-188, RG-316

This document was generated on Dec 29, 2025