


[Labels](#) / [Circuit Board Labels](#) / [Not for Wash Polyester Labels](#) /

BMP61 BMP71 TLS 2200 WorkHorse Polyester Labels

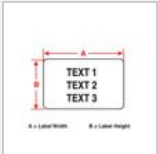

BMP61 BMP71 TLS 2200 WorkHorse Polyester Labels

Part Number:

PTL-7-423

Label/Tape Size:

0.5 in H x 0.5 in W

Material:

Polyester

For Use with Printer:

BMP®61 Labeling System, BMP®71 Label
Printer, TLS 2200® Thermal Labeling
System, TLS-PC LINK™ Thermal Labeling

System

Material Number:

B-423

Color:

White

ADD TO CART

1

OVERVIEW

Permanent Polyester (B-423) is ideal for electronic PCB and component identification, bar code labels, rating plates and solar panel identification.

- Glossy white finish with permanent acrylic is thermal transfer printable
- RoHS compliant to 2005/618/EC MCV amendment to RoHS Directive 2002/95/EC; UL approved; CSA accepted
- Meets requirements of a halogen-free material per DIN VDE 0472 part 815
- Service temperature of -94 to 230° F (-70 to 110° C)

SPECIFICATIONS

Material Number	B-423
Catalog Page #	348
Dimensions	0.5 in H x 0.5 in W
UOM	Roll of 500 Labels
Finish	Gloss
Indoor or Outdoor Use	Outdoor Use
Label/Tape Size	0.5 in H x 0.5 in W
Maximum Service Temperature °F	230 °F
Minimum Service Temperature °F	-94 °F
Pre-Printed Areas on Label	Colored Write-On Area
Printable Area Dimensions	0.5 in H x 0.5 in W
Printable Area Height	0.5 in
Printable Area Width	0.5 in
Product Number	18327
UPC	662820183273
Quantity per Roll	500
Quantity per Dow	1

Secondary Label Included	Secondary Label is Not Included
Thickness	0.003 in
Trade Name	BMP®61 BMP®71 TLS 2200® TLS-PC Link™ WorkHorse®
Adhesive Type	Acrylic
Applications	Asset Tracking, Barcode Labeling, Circuit Board ID - Through Hole Top, Component & Equipment ID, General & Industrial ID, Laboratory ID - Bottle, Tube & Vial, Laboratory ID - Eppendorf Tube, Laboratory ID - Petri Dish, Rating Plates, Solar Panel ID
Color	White
For Use with Printer	BMP®61 Labeling System, BMP®71 Label Printer, TLS 2200® Thermal Labeling System, TLS-PC LINK™ Thermal Labeling System
Header	No Header
Label/Media Format	Roll
Language	No Text
Material	Polyester
Print Technology	Thermal Transfer
Resistance Properties	Abrasion-Resistant, Chemical-Resistant, Corrosion-Resistant, Humidity-Resistant, UV-Resistant, Weather-Resistant
Shape	Square
Suggested Ribbon Series	R4400, R6000, R6200



Solutions

Floor Marking Guide
GHS Label Compliance
Lockout Tagout Compliance
Arc Flash Labeling Requirements
Cable and Wire Label Options
Product and Barcode Labeling
Brand Protection Solutions

Services

Lockout Tagout Services
Arc Flash Services
Confined Space Services
Visual Workplace Services
Hazcom GHS Services
Software Programming & Integration
Label Template & File Conversion
Printer Use & Training
Printer Preventative Maintenance
Toll and Custom Coating

Help

Contact Us
Knowledge Center
Printer Drivers & Firmware
Brady Software Updates
Safety Data Sheets
Technical Data Sheets
WEEE-RoHS Compliance
Product Certification
Printer Registration

Resources

Find a Distributor
Printer Selection Tool
Label Selection Tool
Digital Catalog
Request a Catalog
Interactive Facility Map



Brady
(NYSE:BRC)
is a
manufacturer
of complete
solutions
that
identify and
protect
people,
products
and places.
Brady's
products
help
customers
increase
safety,
security,
productivity
and
performance
and include
high-
performance
labels,
signs, safety
devices,
printing
systems
and
software.

Contact
6555
W.
Good
Hope
Rd.
Milwaukee
WI
53223
Phone:
888-
250-
3082
Hours:
7am-
6pm
CST
Monday
-
Thursday;
Friday
7am-
5pm
CST

About
Corporation
Privacy
Policy
Terms
and
Conditions
Terms
of Use
ISO
Certificates

Other
Brady
Sites
Distributor
Portal
International
Sites
Safety
Services
&
Software
Smart
ID
Brand
Protection



2018 Brady Worldwide, Inc.