

# Actuator

03-  
810.001



<https://www.eao.com/p/03-810.001>

Your product:

---



03-810.001  
Actuator

#### PRODUCT RANGE

**Product Status:** Not Recommended for new design

#### FRONT

**Front form:** Rectangular

#### MOUNTING

**Design:** Flush

**Mounting cut-out:** 21.2 mm x 41.2 mm

**Mounting type:** Panel mounting

#### ELECTRICAL CHARACTERISTICS

**Switching voltage and switching current:** 10 VAC ... 55 VAC, 25 mA  
10 VDC ... 75 VDC, 15 mA

**Operating voltage:** 10 - 55 V AC

#### MECHANICAL CHARACTERISTIC

**Terminal:** Screw terminal

**Tightening torque:** Fixing sleeve max. 0.2 Nm, Screw terminal 0.8 Nm

**Weight:** 0.06 kg

#### ACOUSTICAL CHARACTERISTICS

**Tone frequency:** ca. 2.8 kHz

## AMBIENT CONDITION

**IP Protection:** IP40 front side, according to DIN EN 60529

**Operating temperature:** - 20 °C ... + 60 °C

**Storage temperature:** - 30 °C ... + 70 °C

## CERTIFICATE

**Conformities:** CE, UKCA, 2011 / 65 / EC (RoHS), 2014 / 30 / EU (EMC)

**REACH:** REACH compliant


**RoHS:** RoHS compliant

## OTHER


**Short Description:** Actuator, 21.2 mm x 41.2 mm, Rectangular, Screw terminal

**Buzzer system:** Electronic non-contacting buzzer with IC oscillator

**Wiring diagrams:**

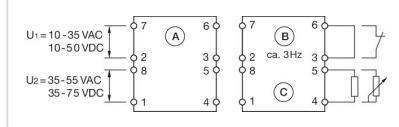

**Mounting cut-outs:**

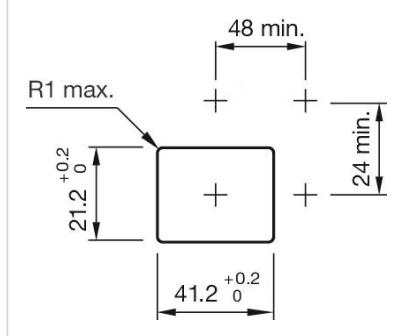

**Dimension drawings:**

