




&lt; List of part numbers with package codes &gt;

GRM31A5C2E562GWA1D , GRM31A5C2E562GWA1J

## Shape

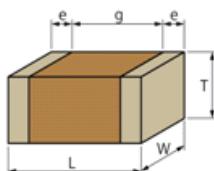

L size	$3.2 \pm 0.2\text{mm}$
W size	$1.6 \pm 0.2\text{mm}$
T size	$1.0 +0/-0.3\text{mm}$
External terminal width e	0.3mm min.
Distance between external terminals g	1.5mm min.
Size code in inch(mm)	1206 (3216M)

## References

Packaging	Specifications	Minimum quantity
D	$\varnothing 180\text{mm}$ Paper taping	4000
J	$\varnothing 330\text{mm}$ Paper taping	10000

Mass (typ.)
1 piece

## Specifications

Capacitance	$5600\text{pF} \pm 2\%$
Rated voltage	250Vdc
Temperature characteristics (complied standard)	C0G(EIA)
Temperature coefficient	$0 \pm 30\text{ppm}/^\circ\text{C}$
Temperature range of temperature characteristics	25 to $125^\circ\text{C}$
Operating temperature range	-55 to $125^\circ\text{C}$

### Attention

1. This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, its specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.

2. This datasheet has only typical specifications because there is no space for detailed specifications.

Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.