
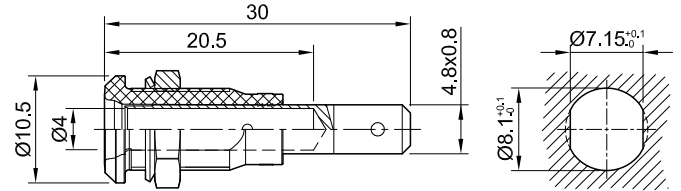


LB4H-IF/A

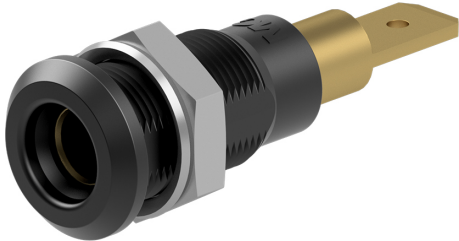

Item number 64.3040-*

Insulated, Ø 4 mm, rigid. Machined brass. The socket can be screw-mounted in predrilled panels. Flat connecting tab 4.8 mm x 0.8 mm.

Technical data	
Diameter of plug system	4 mm
Rated Values	30 V, 25 A / 60 V, 25 A
Surface treatment electrical contact	Au
Base material electrical contact	CuZn
Standard color(s) *	20 21 22 23 24 25 26 27 28 29
Thread	M8x0,5
Component parts	BI-LB4x-IF/A
Supplied assembly material	MU/M8x0,5