


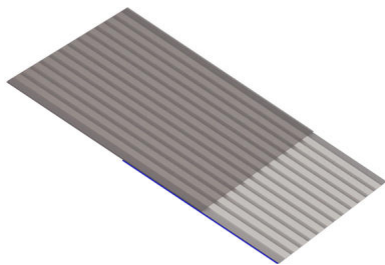

**Part Number :** [982660128](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC  
Jumper, Opposite Side Contacts (Type D), 152.00mm  
Cable Length, Tin (Sn) Plating, 12 Circuits  
**Series Number :** 98266  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [982660128 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-98266-001-001.pdf](#)

## Product Environment Compliance

### Compliance

|                    |                                                                                                              |
|--------------------|--------------------------------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                                                 |
| China RoHS         | <br>per SJ/T 11365-2006 |
| EU ELV             | Not Relevant                                                                                                 |
| Low-Halogen Status | Not Low-Halogen per IEC<br>61249-2-21                                                                        |
| REACH SVHC         | Not Contained per D(2025)4165-DC<br>(25 June 2025)                                                           |
| EU RoHS            | Compliant per EU 2015/863                                                                                    |

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

|              |                                                                                                                           |
|--------------|---------------------------------------------------------------------------------------------------------------------------|
| Status       | Active                                                                                                                    |
| Category     | Flat-Flexible Cable (FFC)                                                                                                 |
| Series       | 98266                                                                                                                     |
| Description  | 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 152.00mm Cable Length, Tin (Sn) Plating, 12 Circuits |
| Comments     | Contacts on opposite sides, Type D                                                                                        |
| Product Name | Premo-Flex FFC Jumper                                                                                                     |
| UPC          | 756054767610                                                                                                              |

**Electrical**

|                               |        |
|-------------------------------|--------|
| Current - Maximum per Contact | 0.5A   |
| Voltage - Maximum             | 60V AC |

**Physical**

|                           |                   |
|---------------------------|-------------------|
| Cable Length              | 152.00mm          |
| Circuits (Loaded)         | 12                |
| Contact Layout Type       | D (opposite side) |
| Design Feature            | Extra-Flexible    |
| Material - Plating Mating | Tin               |
| Net Weight                | 0.598/g           |
| Packaging Type            | Bag               |
| Pitch - Mating Interface  | 0.50mm            |

|                               |                 |
|-------------------------------|-----------------|
| Temperature Range - Operating | -40° to +105°C  |
| Termination Style             | FFC Connector   |
| Wire/Cable Type               | Flat Flex Cable |
| Wire Size (AWG)               | N/A             |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                                                                                                                | Part Number                      |
|------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------|
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 12 Circuits, Tin-Silver-Bismuth Plating                                   | <u><a href="#">525591272</a></u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 12 Circuits, Tin-Bismuth                                  | <u><a href="#">527451296</a></u> |
| Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 12 Circuits, Tin-Bismuth Plating                       | <u><a href="#">527461270</a></u> |
| 0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Tin Bismuth Plating, Short Terminal Type, Black, 12 Circuits | <u><a href="#">781191210</a></u> |
| 0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Tin Bismuth Plating, Long Terminal Type, Black, 12 Circuits   | <u><a href="#">781271210</a></u> |

---

This document was generated on Sep 18, 2025