


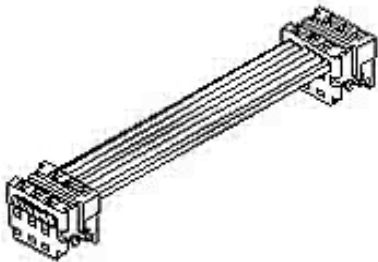

**Part Number :** [923152025](#)  
**Product Description :** Picoflex PF-50 IDT-to-Picoflex  
PF-50 IDT Cable Assembly, 0.25m Length, Tin (Sn)  
Plating, 20 Circuits  
**Series Number :** 92315  
**Status :** Active  
**Product Category :** Power and Signal Cable  
Assemblies



## Documents & Resources

### Drawings

[923152025 sd.pdf](#)

### 3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

### Specifications

[908140000-AS-000.pdf](#)

[PS-99020-0011-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

### [Compliance Statements](#)

- EU RoHS

- REACH SVHC
- Low-Halogen

#### Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

#### Substances of Interest

- PFAS

#### EU RoHS Certificate of Compliance

#### Additional Product Compliance Information

## Part Details

### General

Status	Active
Category	Power and Signal Cable Assemblies
Series	92315
Description	Picoflex PF-50 IDT-to-Picoflex PF-50 IDT Cable Assembly, 0.25m Length, Tin (Sn) Plating, 20 Circuits
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Picoflex IDT-to-IDT
Product Name	Picoflex
UPC	800754779746

### Electrical

Current - Maximum per Contact	1.2A
Voltage - Maximum	250V

### Physical

Cable Length	0.25m
Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	Natural
Gender	Female-Female
Lock to Mating Part	None

Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	10.870/g
Number of Rows	2
Packaging Type	Bag
Pitch - Mating Interface	1.27mm
Plating min - Mating	2.032µm
Plating min - Termination	2.032µm
Single Ended	No
Termination Interface Style	IDT or Pierce
Waterproof / Dustproof	No
Wire/Cable Type	PVC, Ribbon Cable
Wire Size (AWG)	28

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Picoflex PF-50 Vertical Low Profile Headers	<u><a href="#">90325</a></u>
Picoflex PF-50 Vertical Low Profile Headers	<u><a href="#">90779</a></u>
Picoflex PF-50 Vertical Surface Mount Headers	<u><a href="#">90814</a></u>

---

## Application Tooling

### Global

Description	Part Number
Extractor Tool for Connectors	<u><a href="#">621006000</a></u>