



+ CONNECTORS

STANDARD RECTANGULAR CONNECTORS



✓ Active

TE CONNECTIVITY (TE)
DMC-M 04-12 SN
DEUTSCH

DMC-M 04-12 SN
TE Internal Number: ZPF000000000015209

Always EU RoHS/ELV Compliant
Product Type **Connector**
Contact Plating Material **Gold Over Copper**

Catalog Pages/Data Sheets

 
 
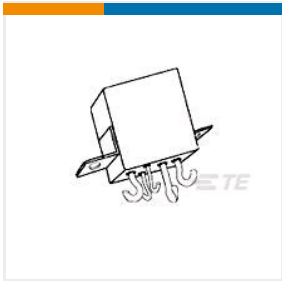
[DMC-M Series Single Module EN4165](#)
PDF
English

Please review product documents or [contact us](#) for the latest agency approval information.



Product Type Features	Product Type	Connector
Configuration Features	Keying	N
Contact Features	Contact Plating Material	Gold Over Copper
	Contact Size	12
	Contact Type	Standard Female Contact
	Contact Style	Crimp
Housing Features	Housing Material	Aluminum
Usage Conditions	Operating Temperature Range (°C)	-55 – 175
Product Compliance	Statement of Compliance PDF VIEW ALL PRODUCT COMPLIANCE	

Customers Also Bought

STANDARD RECTANGULAR CONNECTORS	RECTANGULAR BACKSHELLS & CLAMPS	STANDARD RECTANGULAR CONNECTORS	MID-RANGE RELAYS
			
DMC-MD 80 W 01 DMC-MD 80 W 01	732-8052-00 WA 732-8052-00 WA	DMC-M 20-22 PN DMC-M 20-22 PN	FCA-125-19=M6106/19 019 FCA-125-19

