

16

1633 02


Power supply connectors



Power supply plug,
5.5 mm x 2.1 mm, straight version, with solder eyes and
bend protection

16

1633 02

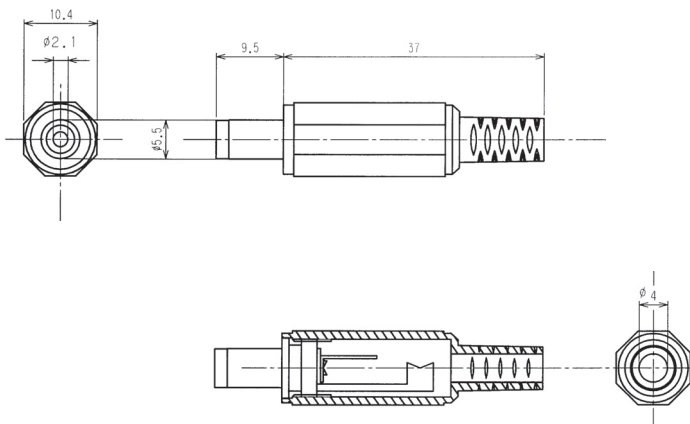

Environmental conditions

Temperature range -20 °C/+70 °C

Materials

Insulating body	PF
Contact	Cu alloy, nickel-plated
Insulation	POM
Housing	PE

Mechanical data

Outer diameter	5.5 mm
Inner diameter	2.1 mm

Connectable conductors for solder area

Cable diameter	4 mm
----------------	------

Electrical data (at T_{amb} 20 °C)

Rated current	3 A
Rated voltage	24 V DC
Rated impulse voltage	500 V/60 s
Insulation resistance	≥ 100 MΩ

Associated products

Counterparts		
↗ 1610 06	↗ 1613 14	↗ 1613 18
↗ 1613 28	↗ 1613 30	↗ 1613 32
↗ 1614 09	↗ 1614 14	↗ 1614 19
↗ NEB 21 R-C	↗ NEB/J 21	↗ NEB/J 21 C
↗ NEB/J 21 R	↗ NEK/J 210	

16

1633 02

Designation	Pole Number	PU (Pieces)	MDQ (Pieces)
1633 02	2	100	500

Packaging:

in bulk, in a cardboard box or a plastic bag