


MMZ0603S100CT000

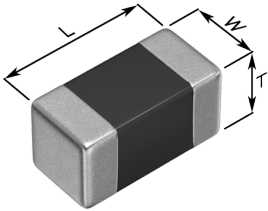

Applications	 Commercial Grade
Feature	 Signal line
Series	MMZ
Status	 Production
Brand	TDK





Size	
Length(L)	0.60mm ±0.03mm
Width(W)	0.30mm ±0.03mm
Thickness(T)	0.30mm ±0.03mm
Recommended Land Pattern (A)	0.25mm Nom.
Recommended Land Pattern (B)	0.30mm Nom.
Recommended Land Pattern (C)	0.30mm Nom.

Electrical Characteristics	
Impedance at 100MHz	10Ω ±5Ω
Rated Current	1A
DC Resistance (Max.)	50mΩ

Other	
Operating Temp. Range (Including Self-Temp. Rise)	-55 to 125°C
Soldering Method	Reflow Iron Soldering
AEC-Q200	NO
Packing	Punched (Paper)Taping [180mm Reel, Tape width 8mm]
Package Quantity	15000pcs
Weight	0.0003g



Characteristic Graphs(This is reference data, and does not guarantee the products characteristics.)

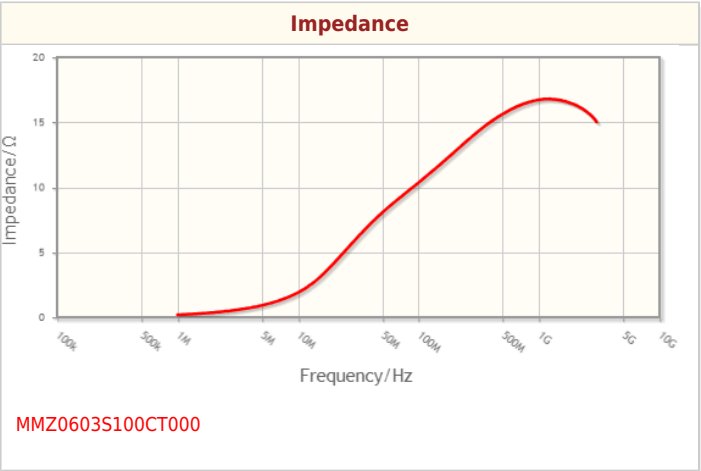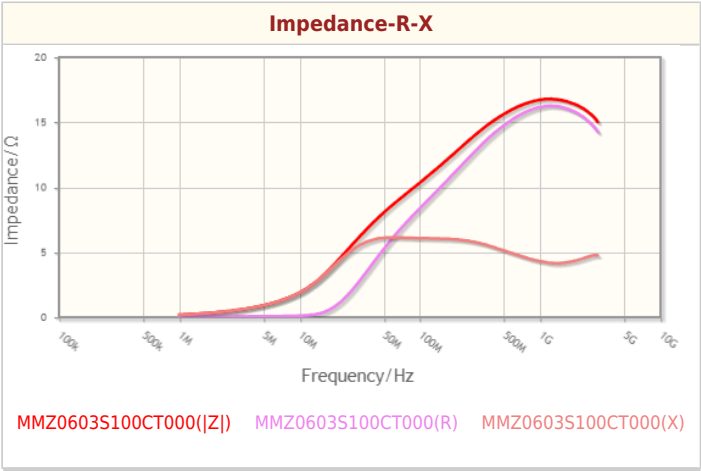



Associated Images

