

WS2813B Digital RGB LED Flexi-Strip 144 LED - 1 Meter

SKU 104990304


IN STOCK 33 Available

- 1 +

 
ADD TO CART

[Description](#)
[Best-sellers](#)
[Technical Details](#)
[Questions and Answers](#)
[View History](#)

Description

WS2813 is an upgraded version of WS2812.

Single pixel control. Dual signal transmission, one pixel damaged will not affect the other LEDs working.



Digital RGB LED Flexi-Strip is an intelligent light source consist s of WS2813B RGB LED with Integrated Driver Chip. The control circuit and RGB chip are integrated in a package of 5050 components.

This LED flexible strip is a full-color that external control for each lamp beads. It with high brightness, can achieve effects of full color running water, chasing and scan.

The RGB LED chips with low driving voltage, environmental protection and energy saving, high brightness, scattering angle is large, good consistency, low power, long life and other advantages. The control chip integrated in LED above becoming more simple circuit, small volume, convenient installation.

Features

 
- Working Volatge:DC 5V
- Working Current:8.64A/meter
- Working Temperature:-40°C ~ 70°C
- Storage Temperature:-50°C ~ 80°C
- Max Watt:43.2W/meter
- IC Size:WS2813B
- Pixel Color:RGB
- Service Life:50,000H


Specification

Glowing effect:



Distribution wiring diagram:



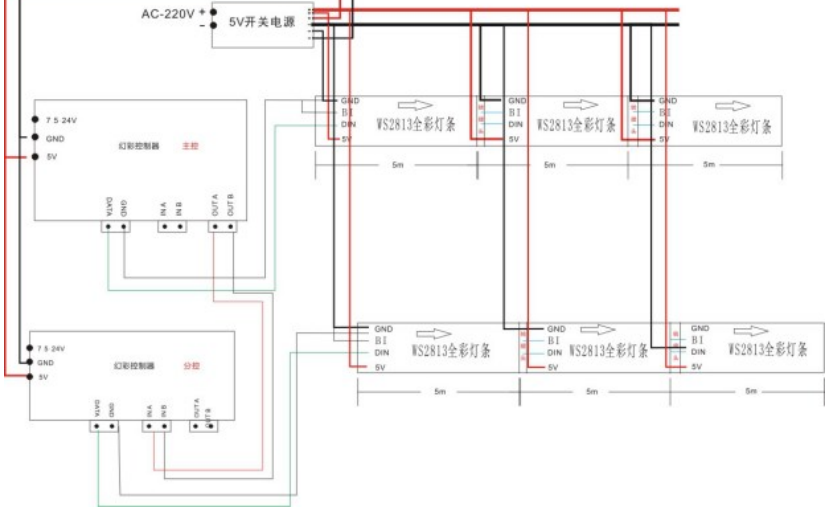

Part List

1 x WS2813B RGB Strip

Best-sellers



38mm 8x8 square matrix L...



Grove - 4 pin Female Jump...



Micro USB Cable - 48cm




ATX Breakout Board V1.1 ...

Technical Details


Dimensions	140mm x 110mm x 24mm
Weight	G.W 40g
Battery	Exclude

Questions and Answers


Have a question about this? Ask people who own it.

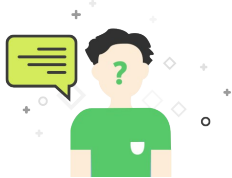


View History




EL Tape - Yellow 1m



EL Panel - Yellow 10cm x 1...

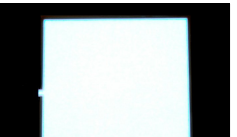

EL Panel - White 10cm x 10...

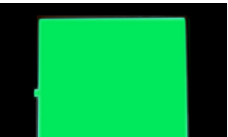

EL Panel - Green 10cm x 10...

