
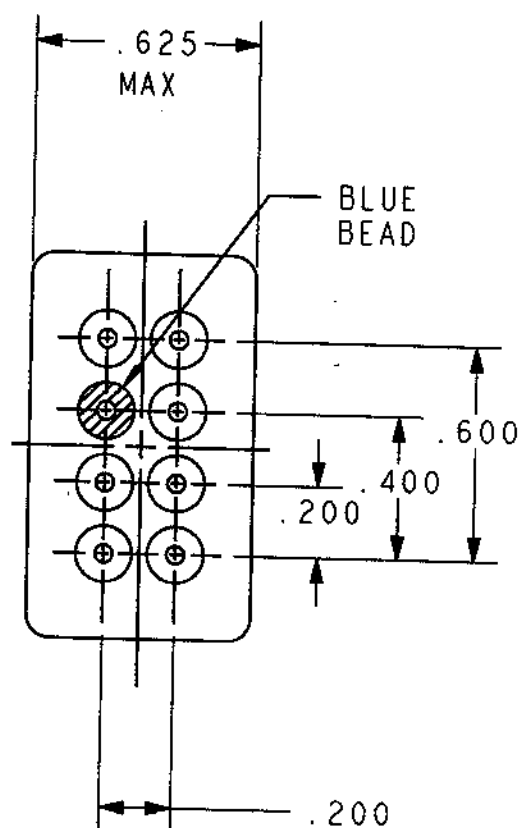


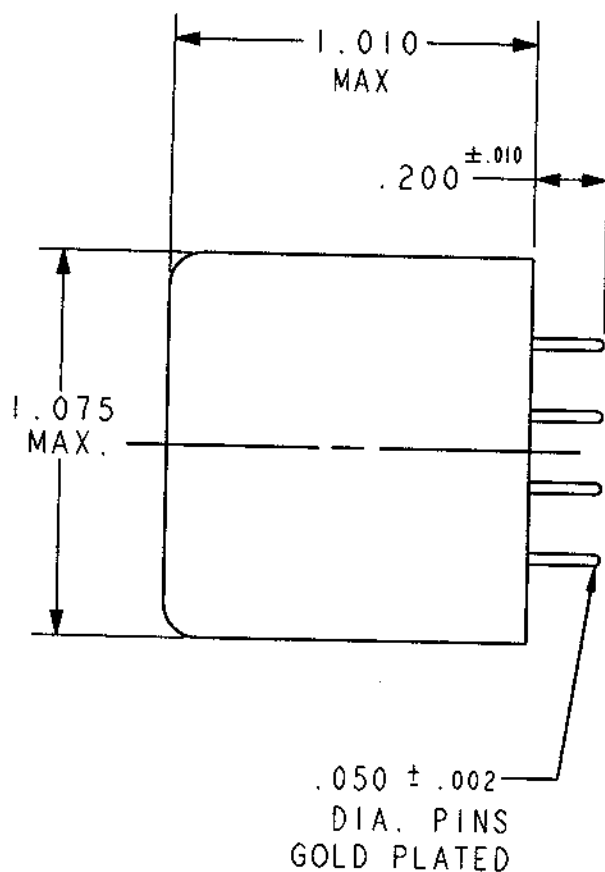

REV. 2
DCO 102710

COIL: @ 25°C

RESISTANCE 300 OHMS $\pm 10\%$

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.0 VDC

MUST RELEASE 7.0 VDC MAX, 2.3 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 50 g's 11 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.

OPERATE BOUNCE 5 MS MAX.

RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

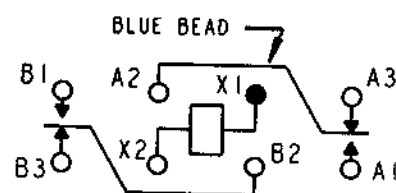

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC
5 AMPS 115 VAC/400 Hz RESISTIVE
50,000 OPERATIONS

DR. BSH 8/17/01 CK. TLG 8-20-01

CII Technologies
advanced control electronic solutions

CUST. OPL
CUST. NO. M5757/23-005 REV.

"07" RELAY

B07D034BC2-0053