




Color: white

Similar to illustration

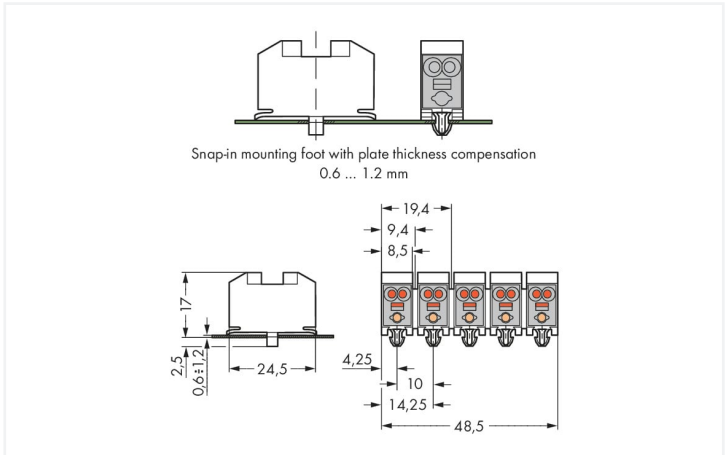

Dimensions in mm

Electrical data

Ratings per	IEC/EN 60664-1		
Overvoltage category	III	III	II
Pollution degree	3	2	2
Nominal voltage	-	400 V	-
Rated surge voltage	-	4 kV	-
Rated current	-	18 A	-

Connection data

Connection points	16
Total number of potentials	4
Number of connection types	1

Connection 1	
Connection technology	PUSH WIRE®
Strip length	8 ... 9 mm / 0.31 ... 0.35 inches
Pole number	4

Physical data

Width	38.5 mm / 1.516 inches
Height	19.5 mm / 0.767 inches
Depth	24.5 mm / 0.965 inches

Material data

Note (material data)	Information on material specifications can be found here
Color	white
Material group	I
Insulation material	Polyamide (PA66)
Flammability class per UL94	V0
Fire load	0.216 MJ
Weight	13.4 g



Commercial data		
Product Group	8 (Misc. Chassis Mount Blocks)	
eCl@ss 10.0	27-14-11-04	
eCl@ss 9.0	27-14-11-04	
ETIM 8.0	EC000446	
ETIM 7.0	EC000446	
PU (SPU)	500 pcs	
Packaging type	Bag	
Country of origin	DE	
GTIN	4044918430050	
Customs tariff number	85369010000	

Environmental Product Compliance	
RoHS Compliance Status	Compliant,No Exemption

Approvals / Certificates

General approvals



Approval	Standard	Certificate Name
CSA DEKRA Certification B.V.	C22.2 No. 158	70048844

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 272-134/101-000	

Documentation

Additional Information			
Technical Section	03.04.2019	pdf 1949.09 KB	

1 Compatible Products

1.1 Optional Accessories

1.1.1 Tool



1.1.1.1 Operating tool



Item No.: [271-120](#)
Push-button; white