

Jumper Along 1x8 red 16A

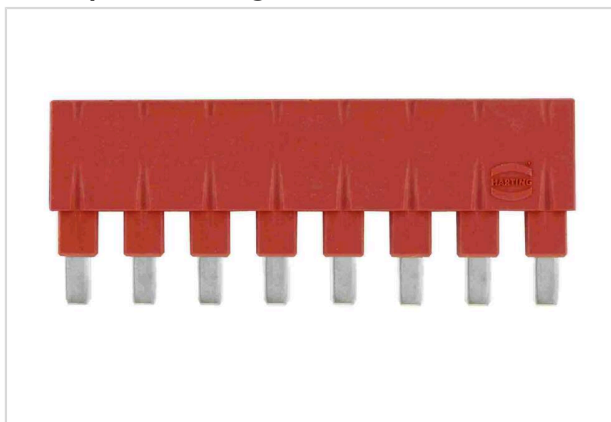


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 9836
Specification	Jumper Along 1x8 red 16A
HARTING eCatalogue	https://b2b.harting.com/09330009836

Identification

Category	Accessories
Series	Han [®] ES Press
Type of accessory	Plug-in jumper
Description of the accessory	1 x 8 Longitudinal

Version

Details	When using plug-in jumpers within Han [®] ES Press hoods of high construction must be used.
---------	--

Technical characteristics

Rated current	16 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Rated voltage acc. to UL	600 V
Insulation resistance	$>10^{10} \Omega$
Contact resistance	$\leq 1 \text{ m}\Omega$
Limiting temperature	-40 ... +125 °C
Mating cycles	≥ 5

Material properties

Material (contacts)	Copper alloy
---------------------	--------------



Pushing Performance
Since 1945

Material properties

Surface (contacts)	Tin plated
Material (accessories)	Polyamide (PA)
Colour (accessories)	RAL 3018 (strawberry red)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Commercial data

Packaging size	5
Net weight	5.96 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140192690
ETIM	EC002943
eCl@ss	27440292 Connector component (accessories)